


## ES EPG/HPG 60 WM 150

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

### Similar to illustration

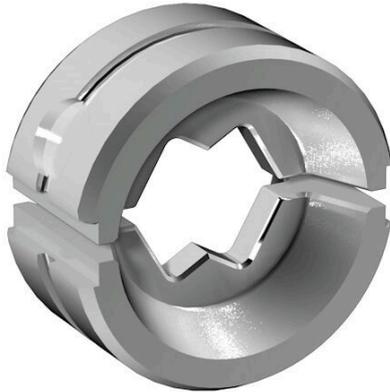

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

|            |   |
|------------|---|
| Version    | Crimping tool insert, 150mm <sup>2</sup> , WM crimp |
| Order No.  | <a href="#">2469620000</a>                          |
| Type       | ES EPG/HPG 60 WM 150                                |
| GTIN (EAN) | 405011848387 1                                      |
| Qty.       | 1 items   |

**ES EPG/HPG 60 WM 150**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Dimensions and weights**

|            |          |                 |             |
|------------|----------|-----------------|-------------|
| Depth      | 22 mm    | Depth (inches)  | 0.8661 inch |
| Height     | 42 mm    | Height (inches) | 1.6535 inch |
| Width      | 42 mm    | Width (inches)  | 1.6535 inch |
| Net weight | 117.92 g |                 |             |

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

**Crimp inserts**

|                      |      |                            |     |
|----------------------|------|----------------------------|-----|
| Crimping width       | 5 mm | Crimp cross-section copper | 150 |
| Crimping width in mm | 5    |                            |     |

**Description of contact**

|                                   |                       |                                   |                     |
|-----------------------------------|-----------------------|-----------------------------------|---------------------|
| Type of contact                   | Euro series cable lug | Conductor cross-section, max. AWG | 5/0                 |
| Conductor cross-section, min. AWG | 5/0                   | Crimping range, max.              | 150 mm <sup>2</sup> |

**tool data crimping**

|                         |                             |
|-------------------------|-----------------------------|
| Crimping type/profile   | WM crimp                    |
| Cable lug cross section | nominal 150 mm <sup>2</sup> |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001282    | ETIM 9.0    | EC001282    |
| ETIM 10.0   | EC001282    | ECLASS 14.0 | 21-04-90-90 |
| ECLASS 15.0 | 21-04-90-90 |             |             |

## ES EPG/HPG 60 WM 150

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | EPG 60                     | Version   |
| Order No.  | <a href="#">2453810000</a> | Pressing tools, Tools, Pressing tool, 6mm <sup>2</sup> , 300mm <sup>2</sup> , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping |
| GTIN (EAN) | 4050118468434              |   |
| Qty.       | 1 ST                       |   |
| Type       | HPG 60                     | Version   |
| Order No.  | <a href="#">2453820000</a> | 6mm <sup>2</sup> , 300mm <sup>2</sup> , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping                                       |
| GTIN (EAN) | 4050118468427              |   |
| Qty.       | 1 ST                       |   |

### 150 mm<sup>2</sup>



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

### General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | KRN-M8/-150                | Version  |
| Order No.  | <a href="#">1495700000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305333              |  |
| Qty.       | 25 ST                      |  |
| Type       | KRN-M10/-150               | Version  |
| Order No.  | <a href="#">1495710000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305159              |  |
| Qty.       | 25 ST                      |  |
| Type       | KRN-M12/-150               | Version  |
| Order No.  | <a href="#">1495720000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305296              |  |
| Qty.       | 25 ST                      |  |

## ES EPG/HPG 60 WM 150

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | KRN-M14/-150               | Version  |
| Order No.  | <a href="#">1495810000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305500              |  |
| Qty.       | 25 ST                      |  |
| Type       | KRN-M16/-150               | Version  |
| Order No.  | <a href="#">1495730000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305395              |  |
| Qty.       | 25 ST                      |  |
| Type       | KRN-M20/-150               | Version  |
| Order No.  | <a href="#">1495740000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305357              |  |
| Qty.       | 25 ST                      |  |
| Type       | KRN-M6/-150 S              | Version  |
| Order No.  | <a href="#">1494440000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118303964              |  |
| Qty.       | 10 ST                      |  |
| Type       | KRN-M8/-150 S              | Version  |
| Order No.  | <a href="#">1494940000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118304701              |  |
| Qty.       | 10 ST                      |  |
| Type       | KRN-M10/-150 S             | Version  |
| Order No.  | <a href="#">1494950000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118304473              |  |
| Qty.       | 10 ST                      |  |
| Type       | KRN-M12/-150 S             | Version  |
| Order No.  | <a href="#">1494970000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118304459              |  |
| Qty.       | 10 ST                      |  |
| Type       | KWN-M8/-150 90             | Version  |
| Order No.  | <a href="#">1494490000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118304107              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M10/150 90             | Version  |
| Order No.  | <a href="#">1494500000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118303896              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M12/-150 90            | Version  |
| Order No.  | <a href="#">1494510000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118304305              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M16/-150 90            | Version  |
| Order No.  | <a href="#">1494520000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118303995              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M20/-150 90            | Version  |
| Order No.  | <a href="#">1494530000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118304206              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M8/-150 45             | Version  |
| Order No.  | <a href="#">1496430000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118306071              |  |
| Qty.       | 25 ST                      |  |

## ES EPG/HPG 60 WM 150

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | KWN-M10/-150 45            | Version  |
| Order No.  | <a href="#">1496440000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305777              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M12/-150 45            | Version  |
| Order No.  | <a href="#">1496450000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305906              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M16/-150 45            | Version  |
| Order No.  | <a href="#">1496470000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118306132              |  |
| Qty.       | 25 ST                      |  |
| Type       | KWN-M20/-150 45            | Version  |
| Order No.  | <a href="#">1496480000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> - 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118305739              |  |
| Qty.       | 25 ST                      |  |
| Type       | VSTN/-150                  | Version  |
| Order No.  | <a href="#">1497380000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> , None                |
| GTIN (EAN) | 4050118306958              |  |
| Qty.       | 25 ST                      |  |
| Type       | KP-M8/-150                 | Version  |
| Order No.  | <a href="#">1498290000</a> | cable lug, terminal end, 150 mm <sup>2</sup>   |
| GTIN (EAN) | 4050118307399              |  |
| Qty.       | 25 ST                      |  |

10 mm<sup>2</sup>

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | KP-M10/-150                | Version                                      |
| Order No.  | <a href="#">1498310000</a> | cable lug, terminal end, 150 mm <sup>2</sup> |
| GTIN (EAN) | 4050118307801              |  |
| Qty.       | 25 ST                      |  |

## ES EPG/HPG 60 WM 150

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

150 mm<sup>2</sup>150 mm<sup>2</sup>

The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

## General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | KP-M12/-150                | Version   |
| Order No.  | <a href="#">1498320000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307658              |   |
| Qty.       | 25 ST                      |   |
| Type       | KP-M14/-150                | Version   |
| Order No.  | <a href="#">1498580000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118308112              |   |
| Qty.       | 25 ST                      |   |
| Type       | KP-M16/-150                | Version   |
| Order No.  | <a href="#">1498330000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307641              |   |
| Qty.       | 25 ST                      |   |
| Type       | KP-M20/-150                | Version   |
| Order No.  | <a href="#">1498340000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307740              |   |
| Qty.       | 25 ST                      |   |
| Type       | KWPN-M8/-150 90            | Version   |
| Order No.  | <a href="#">1497790000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307085              |   |
| Qty.       | 25 ST                      |   |
| Type       | KWPN-M10/-150 90           | Version   |
| Order No.  | <a href="#">1497810000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307221              |   |
| Qty.       | 25 ST                      |   |
| Type       | KWPN-M12/-150 90           | Version   |
| Order No.  | <a href="#">1497820000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307306              |   |
| Qty.       | 25 ST                      |   |
| Type       | KWPN-M16/-150 90           | Version   |
| Order No.  | <a href="#">1497830000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118307160              |   |
| Qty.       | 25 ST                      |   |
| Type       | KWPN-M20/150 90            | Version   |
| Order No.  | <a href="#">1496680000</a> | cable lug, terminal end, 150 mm <sup>2</sup>                              |
| GTIN (EAN) | 4050118306088              |   |
| Qty.       | 25 ST                      |   |
| Type       | VPN/-150                   | Version   |
| Order No.  | <a href="#">1498710000</a> | cable lug, terminal end, 150 mm <sup>2</sup> , 150 mm <sup>2</sup> , None |
| GTIN (EAN) | 4050118308129              |   |
| Qty.       | 25 ST                      |   |

## ES EPG/HPG 60 WM 150

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | VPLN/-150                  | Version |  |
| Order No.  | <a href="#">1492970000</a> |         | cable lug, terminal end,150 mm <sup>2</sup> ,150 mm <sup>2</sup> ,None |
| GTIN (EAN) | 4050118302912              |         |  |
| Qty.       | 50 ST                      |         |  |
| Type       | VSTN/150                   | Version |  |
| Order No.  | <a href="#">1493120000</a> |         | cable lug, terminal end,150 mm <sup>2</sup> ,150 mm <sup>2</sup> ,None |
| GTIN (EAN) | 4050118302905              |         |  |
| Qty.       | 50 ST                      |         |  |