


## ES EPG/HPG 60 WM 240

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

### Similar to illustration

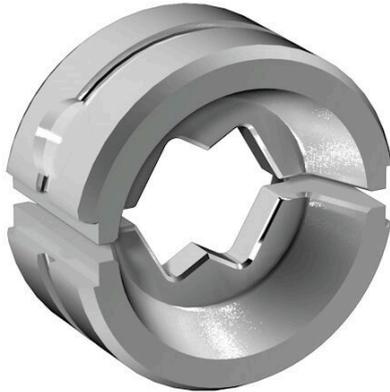

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

Version	Crimping tool insert, 240mm <sup>2</sup> , WM crimp
Order No.	<a href="#">2469640000</a>
Type	ES EPG/HPG 60 WM 240
GTIN (EAN)	4050118484052
Qty.	1 items

**ES EPG/HPG 60 WM 240**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Dimensions and weights**

Depth	22 mm	Depth (inches)	0.8661 inch
Height	42 mm	Height (inches)	1.6535 inch
Width	42 mm	Width (inches)	1.6535 inch
Net weight	117 g		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Crimp inserts**

Crimping width	5 mm	Crimp cross-section copper	240
Crimping width in mm	5		

**Description of contact**

Type of contact	Euro series cable lug	Conductor cross-section, max. AWG	450
Conductor cross-section, min. AWG	450	Crimping range, max.	240 mm <sup>2</sup>

**tool data crimping**

Crimping type/profile	WM crimp
Cable lug cross section	nominal 240 mm <sup>2</sup>

**Classifications**

ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

## ES EPG/HPG 60 WM 240

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

Type	EPG 60	Version
Order No.	<a href="#">2453810000</a>	Pressing tools, Tools, Pressing tool, 6mm <sup>2</sup> , 300mm <sup>2</sup> , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
GTIN (EAN)	4050118468434	
Qty.	1 ST	
Type	HPG 60	Version
Order No.	<a href="#">2453820000</a>	6mm <sup>2</sup> , 300mm <sup>2</sup> , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
GTIN (EAN)	4050118468427	
Qty.	1 ST	

### 240 mm<sup>2</sup>



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

### General ordering data

Type	KRN-M8/-240	Version
Order No.	<a href="#">1495480000</a>	cable lug, terminal end, 240 mm <sup>2</sup> , 240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304756	
Qty.	25 ST	
Type	KRN-M10/-240	Version
Order No.	<a href="#">1495490000</a>	cable lug, terminal end, 240 mm <sup>2</sup> , 240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118305050	
Qty.	25 ST	
Type	KRN-M12/-240	Version
Order No.	<a href="#">1495500000</a>	cable lug, terminal end, 240 mm <sup>2</sup> , 240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118305142	
Qty.	25 ST	

## ES EPG/HPG 60 WM 240

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

### Accessories

Type	KRN-M14/-240	Version
Order No.	<a href="#">1497270000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118306842	
Qty.	25 ST	
Type	KRN-M16/-240	Version
Order No.	<a href="#">1495510000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304770	
Qty.	25 ST	
Type	KRN-M20/-240	Version
Order No.	<a href="#">1495520000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118305104	
Qty.	25 ST	
Type	KRN-M10/-240 S	Version
Order No.	<a href="#">1494340000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304039	
Qty.	5 ST	
Type	KRN-M12/-240 S	Version
Order No.	<a href="#">1494350000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118303933	
Qty.	5 ST	
Type	KRN-M16/-240 S	Version
Order No.	<a href="#">1494370000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304046	
Qty.	5 ST	
Type	KWN-M10/-240 90	Version
Order No.	<a href="#">1494590000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304145	
Qty.	25 ST	
Type	KWN-M12/-240 90	Version
Order No.	<a href="#">1494610000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304244	
Qty.	25 ST	
Type	KWN-M16/-240 90	Version
Order No.	<a href="#">1494620000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304237	
Qty.	25 ST	
Type	KWN-M20/-240 90	Version
Order No.	<a href="#">1494630000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118304138	
Qty.	25 ST	
Type	KWN-M12/-240 45	Version
Order No.	<a href="#">1495400000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118305227	
Qty.	15 ST	
Type	KWN-M16/-240 45	Version
Order No.	<a href="#">1495410000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118305203	
Qty.	15 ST	
Type	KWN-M20/-240 45	Version
Order No.	<a href="#">1495420000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> - 240 mm <sup>2</sup>
GTIN (EAN)	4050118305234	
Qty.	15 ST	

## ES EPG/HPG 60 WM 240

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

Type	VSTN/-240	Version
Order No.	<a href="#">1497400000</a>	cable lug, terminal end,240 mm <sup>2</sup> ,240 mm <sup>2</sup> ,None
GTIN (EAN)	4050118306965	
Qty.	25 ST	
Type	KP-M10/-240	Version
Order No.	<a href="#">1498390000</a>	cable lug, terminal end,240 mm <sup>2</sup>
GTIN (EAN)	4050118307818	
Qty.	20 ST	
Type	KP-M12/-240	Version
Order No.	<a href="#">1498410000</a>	cable lug, terminal end,240 mm <sup>2</sup>
GTIN (EAN)	4050118307672	
Qty.	20 ST	
Type	KP-M14/-240	Version
Order No.	<a href="#">1498530000</a>	cable lug, terminal end,240 mm <sup>2</sup>
GTIN (EAN)	4050118307689	
Qty.	20 ST	
Type	KP-M16/-240	Version
Order No.	<a href="#">1498420000</a>	cable lug, terminal end,240 mm <sup>2</sup>
GTIN (EAN)	4050118307825	
Qty.	20 ST	
Type	KP-M20/-240	Version
Order No.	<a href="#">1498430000</a>	cable lug, terminal end,240 mm <sup>2</sup>
GTIN (EAN)	4050118307832	
Qty.	20 ST	