


ES EPG/HPG 60 WM 300

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Similar to illustration

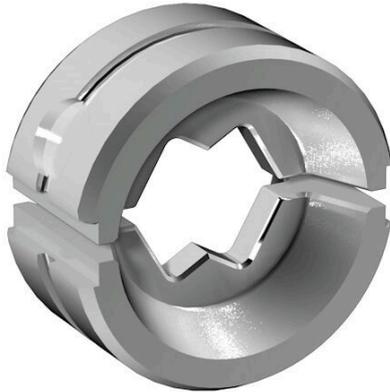

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Version	Crimping tool insert, 300mm ² , WM crimp
Order No.	2469650000
Type	ES EPG/HPG 60 WM 300
GTIN (EAN)	4050118484045
Qty.	1 items

ES EPG/HPG 60 WM 300

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Depth	22 mm	Depth (inches)	0.8661 inch
Height	42 mm	Height (inches)	1.6535 inch
Width	42 mm	Width (inches)	1.6535 inch
Net weight	88 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Crimp inserts

Crimping width	5 mm	Crimp cross-section copper	300
Crimping width in mm	5		

Description of contact

Type of contact	Euro series cable lug	Conductor cross-section, max. AWG	600
Conductor cross-section, min. AWG	600	Crimping range, max.	300 mm ²

tool data crimping

Crimping type/profile	WM crimp
Cable lug cross section	nominal 300 mm ²

Classifications

ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		

ES EPG/HPG 60 WM 300

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Tools



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm²
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

General ordering data

Type	EPG 60	Version
Order No.	2453810000	Pressing tools, Tools, Pressing tool, 6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
GTIN (EAN)	4050118468434	
Qty.	1 ST	
Type	HPG 60	Version
Order No.	2453820000	6mm ² , 300mm ² , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
GTIN (EAN)	4050118468427	
Qty.	1 ST	

300 mm²



The use of insulated connectors guarantees users consistent electrical connection quality in the long term.

- Wide range of insulated and non-insulated cable lugs and connectors
- Tubular cable lugs according to current market standards (Euroseries)
- Compression cable lugs acc. to DIN 46235
- Sheet metal cable lugs acc. to DIN 46234
- Insulated ring cable lugs to DIN 46237
- Insulated pin cable lugs to DIN 46231

General ordering data

Type	KP-M10/-300	Version
Order No.	1498440000	cable lug, terminal end,300 mm ²
GTIN (EAN)	4050118307764	
Qty.	10 ST	
Type	KP-M12/-300	Version
Order No.	1498450000	cable lug, terminal end,300 mm ²
GTIN (EAN)	4050118307788	
Qty.	10 ST	
Type	KP-M14/-300	Version
Order No.	1498550000	cable lug, terminal end,300 mm ²
GTIN (EAN)	4050118307924	
Qty.	10 ST	

ES EPG/HPG 60 WM 300

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Type	KP-M16/-300	Version	
Order No.	1498460000		cable lug, terminal end,300 mm ²
GTIN (EAN)	4050118307870		
Qty.	10 ST		
Type	KP-M20/-300	Version	
Order No.	1498470000		cable lug, terminal end,300 mm ²
GTIN (EAN)	4050118307849		
Qty.	10 ST		