

IE-BHD-VAPM

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



PushPull Power plug-in connector according to PROFINET specification

General ordering data

Version	Power connector, Device flange, PROFINET
Order No.	2493490000
Type	IE-BHD-VAPM
GTIN (EAN)	4050118529104
Qty.	1 items

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (UR) E92202

Dimensions and weights

Height	42 mm	Height (inches)	1.6535 inch
Width	36.2 mm	Width (inches)	1.4252 inch
Length	14.2 mm	Length (inches)	0.5591 inch
Net weight	23 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...80 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Shielding	unshielded	Colour	Silver grey
Housing main material	Zinc diecast, nickel-plated	Type of mounting	4 screws
Protection degree	IP67	Plugging cycles	500
Pollution severity	2	Sealing material	NBR
Type of interlock	Push Pull		

General standards


Certificate No. (UR)	E92202
----------------------	--------

Classifications

ETIM 8.0	EC001121	ETIM 9.0	EC001121
ETIM 10.0	EC001121	ECLASS 14.0	27-44-03-90
ECLASS 15.0	27-44-03-90		

Drawings

Dimensioned drawing

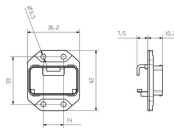

Installation cut-out

