

**ESG 8/20 MM WS VPE1000**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

**Your benefits with MultiMark**

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

**General ordering data**

Version	ESG, Device markers, 8 x 20 mm, white
Order No.	<a href="#">2496810000</a>
Type	ESG 8/20 MM WS VPE1000
GTIN (EAN)	4050118508314
Qty.	1000 items

**ESG 8/20 MM WS VPE1000**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	0.1 mm	Depth (inches)	0.0039 inch
Height	8 mm	Height (inches)	0.315 inch
Width	20 mm	Width (inches)	0.7874 inch
Net weight	0.04 g		

**Temperatures**

Operating temperature range -40...120 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Adhesive	Acrylate adhesive	Version	Self-adhesive, halogen-free
Width	20 mm	UL 94 flammability rating	V-0
Operating temperature range, max.	120 °C	Operating temperature range, min.	-40 °C
Colour	white	Halogen	No
Basic material	Polyester	Printed characters	without
Approval acc. to UL 969	Yes	compatible printer	<a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a>
Operating temperature range	-40...120 °C	Number per roll	1000

**Device markers**

Halogen No

**Classifications**


ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**ESG 8/20 MM WS VPE1000**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

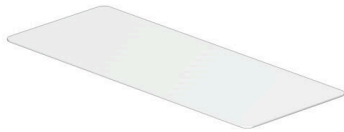

## ESG 8/20 MM WS VPE1000

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	RIBBON MM 76/360 SW	Version	
Order No.	<a href="#">2005080000</a>	Ink ribbon	
GTIN (EAN)	4050118389951		
Qty.	1 ST		

### THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	MULTIMARK ROLLER 115	Version	
Order No.	<a href="#">1357420000</a>		
GTIN (EAN)	4050118160314		
Qty.	1 ST		

### THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	<a href="#">2672590000</a>		
GTIN (EAN)	4050118708097		
Qty.	1 ST		