

**UR67-MP-78-16DIO-12-60M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Product image**

Similar to illustration

More performance. Simplified.

u-remote.

Weidmüller u-remote – our innovative remote I/O concept with IP 67 which focuses purely on user benefits: tailored planning, faster installation, safer start-up, no more down-time. For considerably improved performance and greater productivity.u-remote stands for "More Performance". Simplified

**General ordering data**

|            |   |
|------------|---|
| Version    | Automation Products - u-remote IP67, Sensor-actuator active distributor |
| Order No.  | <a href="#">2512830000</a>  |
| Type       | UR67-MP-78-16DIO-12-60M   |
| GTIN (EAN) | 4050118527780   |
| Qty.       | 1 items   |

## UR67-MP-78-16DIO-12-60M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform  
 UL File Number Search [UL Website](#)  
 Certificate no. (cULus) E141197

### Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Height     | 17.3 mm | Height (inches) | 0.6811 inch |
| Width      | 59.6 mm | Width (inches)  | 2.3465 inch |
| Net weight | 500 g   |                 |             |

### Environmental Product Compliance

RoHS Compliance Status Compliant with exemption  
 RoHS Exemption (if applicable/known) 6c  
 REACH SVHC Lead 7439-92-1  
 SCIP 82327f13-cd27-455a-ab5b-a62e1996dcf8

### Digital inputs

|                    |                              |     |
|--------------------|------------------------------|-----|
| Diagnostic display | Per channel, via LED, red    |     |
| Status indicator   | Per channel, via LED, yellow |     |
| Digital inputs     | Short-circuit protection     | Yes |
|                    | Overload protection          | Yes |
|                    | Reverse polarity protection  | Yes |

### Digital outputs

|                      |                              |     |
|----------------------|------------------------------|-----|
| Diagnostic display   | Per channel, via LED, red    |     |
| Digital outputs      | Short-circuit protection     | Yes |
|                      | Overload protection          | Yes |
|                      | Reverse polarity protection  | Yes |
| Short-circuit proof  | Yes                          |     |
| Output voltage, low  | min. (UL -1)                 |     |
| Status indicator     | Per channel, via LED, yellow |     |
| Output voltage, high | max. 2 V                     |     |

### General data

|                           |       |                   |      |
|---------------------------|-------|-------------------|------|
| UL 94 flammability rating | UL 94 | Protection degree | IP67 |
|---------------------------|-------|-------------------|------|

### Supply voltage

|   |                |
|---|----------------|
| Power consumption of module electronics | 100 mA typical |
|---|----------------|

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001599    | ETIM 9.0    | EC001599    |
| ETIM 10.0   | EC001599    | ECLASS 14.0 | 27-24-26-04 |
| ECLASS 15.0 | 27-24-26-04 |             |             |

**UR67-MP-78-16DIO-12-60M**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**M12**



Protective caps protect unassigned plug-in stations against external influences.

**General ordering data**

|            |                            |  |
|------------|----------------------------|--|
| Type       | SAI-SK-M12                 | Version  |
| Order No.  | <a href="#">9456050000</a> | Protected component assemblies, Protective cap |
| GTIN (EAN) | 4008190304058              |  |
| Qty.       | 30 ST                      |  |
| Type       | SAI-SK-M12-UNI 2029        | Version  |
| Order No.  | <a href="#">2330260000</a> | Protected component assemblies, Protective cap |
| GTIN (EAN) | 4032248592067              |  |
| Qty.       | 20 ST                      |  |
| Type       | SAI-SK STECKER M12         | Version  |
| Order No.  | <a href="#">1781520000</a> | Protective cap, IP20                           |
| GTIN (EAN) | 4032248171835              |  |
| Qty.       | 50 ST                      |  |

**PUR, halogen-free, black (U)**



Sensor/actuator cables are used for wiring sensors and actuators and for transmitting data or power in various applications. The moulded cable offers connected and tested connection of the plug-in connector to the cable ex-works. The cables may be exposed to a wide range of conditions, such as humidity, dust, heat, cold, shock or vibration.

The 7/8" cables tend to be used for power supply applications.

Is there something you have not managed to find or you feel needs explanation? Talk to us!

**General ordering data**

|            |                            |  |
|------------|----------------------------|--|
| Type       | SAIL-7/8W-5-1.5U           | Version  |
| Order No.  | <a href="#">1292180150</a> | Sensor/actuator line, One end without connector, 7/8", Number of poles : 5 (4 + PE), 1.5 m, pin, 90°, Shielded: No, LED: No, Sheath material: PUR, Halogen: No       |
| GTIN (EAN) | 4050118088052              |  |
| Qty.       | 1 ST                       |  |
| Type       | SAIL-7/8G-5-1.5U           | Version  |
| Order No.  | <a href="#">1292170150</a> | Sensor/actuator line, One end without connector, 7/8", Number of poles : 5 (4 + PE), 1.5 m, pin, straight, Shielded: No, LED: No, Sheath material: PUR, Halogen: No  |
| GTIN (EAN) | 4050118088168              |  |
| Qty.       | 1 ST                       |  |
| Type       | SAIL-7/8BW-5-1.5U          | Version  |
| Order No.  | <a href="#">1292200150</a> | Sensor/actuator line, One end without connector, 7/8", Number of poles : 5 (4 + PE), 1.5 m, Socket, angled, Shielded: No, LED: No, Sheath material: PUR, Halogen: No |
| GTIN (EAN) | 4050118088304              |  |
| Qty.       | 1 ST                       |  |

## UR67-MP-78-16DIO-12-60M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | SAIL-7/8BG-5-1.5U          | Version  |
| Order No.  | <a href="#">1292190150</a> | Sensor/actuator line, One end without connector, 7/8", Number of       |
| GTIN (EAN) | 4050118088250              | poles : 5 (4 + PE), 1.5 m, Female socket, straight, Shielded: No, LED: |
| Qty.       | 1 ST                       | No, Sheath material: PUR, Halogen: No                                  |

## Straight



Individual cable lengths are often required nowadays. In order to meet these demands, Weidmüller offers a wide range of plug-in connectors for custom assembly. Male plugs and female sockets for customisable assembly for M8, M12, M16 and 7/8" connections which are highly robust and ideally suited to machine engineering, for instance. The 7/8" round plug-in connectors can transmit large amount of power. The screw connection can be used in a wide range of applications. With this technology the conductor, optionally with wire-end ferrules, can be plugged into connection elements and secured with a screw. It is the classic, cheapest form of connection technology that also supports multi-conductor connections.

## General ordering data

|            |                            |                                  |
|------------|----------------------------|----------------------------------|
| Type       | SAIB-5/9-7/8               | Version                          |
| Order No.  | <a href="#">1292000000</a> | Field attachable connector, 7/8" |
| GTIN (EAN) | 4050118086874              |                                  |
| Qty.       | 1 ST                       |                                  |

## Angled



Individual cable lengths are often required nowadays. In order to meet these demands, Weidmüller offers a wide range of plug-in connectors for custom assembly. Male plugs and female sockets for customisable assembly for M8, M12, M16 and 7/8" connections which are highly robust and ideally suited to machine engineering, for instance. The 7/8" round plug-in connectors can transmit large amount of power. The screw connection can be used in a wide range of applications. With this technology the conductor, optionally with wire-end ferrules, can be plugged into connection elements and secured with a screw. It is the classic, cheapest form of connection technology that also supports multi-conductor connections.

## General ordering data

|            |                            |                                  |
|------------|----------------------------|----------------------------------|
| Type       | SAIBW-5/9-7/8              | Version                          |
| Order No.  | <a href="#">1292020000</a> | Field attachable connector, 7/8" |
| GTIN (EAN) | 4050118086959              |                                  |
| Qty.       | 1 ST                       |                                  |

## UR67-MP-78-16DIO-12-60M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Straight



Individual cable lengths are often required nowadays. In order to meet these demands, Weidmüller offers a wide range of plug-in connectors for custom assembly. Male plugs and female sockets for customisable assembly for M8, M12, M16 and 7/8" connections which are highly robust and ideally suited to machine engineering, for instance. The 7/8" round plug-in connectors can transmit large amount of power. The screw connection can be used in a wide range of applications. With this technology the conductor, optionally with wire-end ferrules, can be plugged into connection elements and secured with a screw. It is the classic, cheapest form of connection technology that also supports multi-conductor connections.

## General ordering data

|            |                            |                                  |
|------------|----------------------------|----------------------------------|
| Type       | SAIS-5/9-7/8               | Version                          |
| Order No.  | <a href="#">1301220000</a> | Field attachable connector, 7/8" |
| GTIN (EAN) | 4050118098150              |                                  |
| Qty.       | 1 ST                       |                                  |

## Angled



Individual cable lengths are often required nowadays. In order to meet these demands, Weidmüller offers a wide range of plug-in connectors for custom assembly. Male plugs and female sockets for customisable assembly for M8, M12, M16 and 7/8" connections which are highly robust and ideally suited to machine engineering, for instance. The 7/8" round plug-in connectors can transmit large amount of power. The screw connection can be used in a wide range of applications. With this technology the conductor, optionally with wire-end ferrules, can be plugged into connection elements and secured with a screw. It is the classic, cheapest form of connection technology that also supports multi-conductor connections.

## General ordering data

|            |                            |                                  |
|------------|----------------------------|----------------------------------|
| Type       | SAISW-5/9-7/8              | Version                          |
| Order No.  | <a href="#">1291980000</a> | Field attachable connector, 7/8" |
| GTIN (EAN) | 4050118087017              |                                  |
| Qty.       | 1 ST                       |                                  |

**UR67-MP-78-16DIO-12-60M**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**M12 straight male - M12 straight male**

Assembled IE cables, PROFINET, Cat. 5, PUR, green, drag-chain compatible, M12



**General ordering data**

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | IE-C5DD4UG0015MCSMCS-E     | Version   |  |
| Order No.  | <a href="#">1025950015</a> | Dragline cable, PROFINET, M12 D-code – IP 67 straight pin, M12 D-code – IP 67 straight pin, Cat.5 (ISO/IEC 11801) / Cat.5e (TIA T568-B), PUR, 1.5 m |  |
| GTIN (EAN) | 4032248776054              |   |  |
| Qty.       | 1 ST                       |   |  |

**Dragline cable Cat.5 PUR - RJ45 IP20 / M12 IP67 straight male**

Assembled IE cables, PROFINET, Cat. 5, PUR, green, drag-chain compatible, M12-RJ45




**General ordering data**

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | IE-C5DD4UG0015MCSA70-E     | Version  |  |
| Order No.  | <a href="#">1044470015</a> | Dragline cable, PROFINET, M12 D-code – IP 67 straight pin, RJ45 IP 20, Cat.5 (ISO/IEC 11801) / Cat.5e (TIA T568-B), PUR, 1.5 m |  |
| GTIN (EAN) | 4032248779062              |  |  |
| Qty.       | 1 ST                       |  |  |

**Screw connection**

M12 plug-in connector in IP 67 available with crew or tension clamp connection

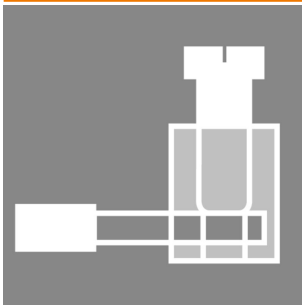

**General ordering data**

|            |                            |                                 |  |
|------------|----------------------------|---------------------------------|--|
| Type       | SAISGS-M-4D-6/8-M12        | Version                         |  |
| Order No.  | <a href="#">1892120000</a> | Field attachable connector, M12 |  |
| GTIN (EAN) | 4032248569380              |                                 |  |
| Qty.       | 1 ST                       |                                 |  |


## UR67-MP-78-16DIO-12-60M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

## Blank

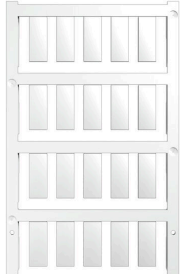

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | ESG-M 8/20 MC NE WS        | Version |  |
| Order No.  | <a href="#">1027290000</a> |         | ESG, Device markers x 20 mm, PA 66, Colour: white, pluggable |
| GTIN (EAN) | 4032248753284              |         |  |
| Qty.       | 200 ST                     |         |  |