


## EL 100 MM BL 30M

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

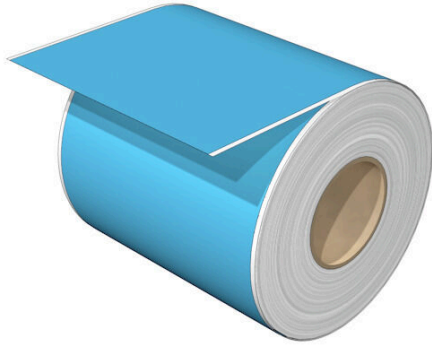

Customised identification: EL

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

### General ordering data

Version	THM, Device markers, 100 x , blue
Order No.	<a href="#">2519030000</a>
Type	EL 100 MM BL 30M
GTIN (EAN)	4050118531084
Qty.	1 items

**EL 100 MM BL 30M**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	0.1 mm	Depth (inches)	0.0039 inch
Height	100 mm	Height (inches)	3.937 inch
Length	30000 mm	Length (inches)	1181.1 inch
Net weight	828 g		

**Temperatures**

Operating temperature range -40...120 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Adhesive	Acrylate adhesive	Version	halogen-free, Self-adhesive
UL 94 flammability rating	V-0	Operating temperature range, max.	120 °C
Operating temperature range, min.	-40 °C	Colour	blue
Halogen	No	Length	30000 mm
Basic material	Polyester	Printed characters	without
Approval acc. to UL 969	Yes	compatible printer	<a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a>
Operating temperature range	-40...120 °C	Number per roll	1


**Device markers**

Halogen No

**Classifications**

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**Drawings**

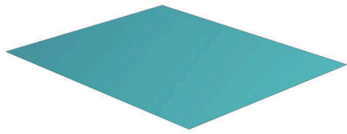

## EL 100 MM BL 30M

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	RIBBON MM 110/360 SW	Version	
Order No.	<a href="#">2005070000</a>	Ink ribbon	
GTIN (EAN)	4050118390049		
Qty.	1 ST		

### THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	THM MMP EXT.RH	Version	
Order No.	<a href="#">1302920000</a>		
GTIN (EAN)	4050118102307		
Qty.	1 ST		
Type	MULTIMARK ROLLER 115	Version	
Order No.	<a href="#">1357420000</a>		
GTIN (EAN)	4050118160314		
Qty.	1 ST		

### THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

## EL 100 MM BL 30M

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version
Order No.	<a href="#">2672590000</a>	
GTIN (EAN)	4050118708097	
Qty.	1 ST	

### Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

### General ordering data

Type	RIBBON MM 110/300 WS	Version
Order No.	<a href="#">2918800000</a>	Ink ribbon
GTIN (EAN)	4099986574878	
Qty.	1 ST	