


H0,14/12 BR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

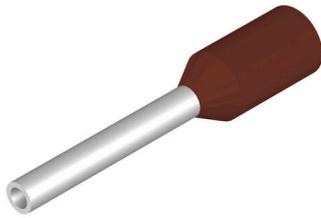

- Weidmüller colour code
- in multipack bag (5 x 100 pcs.)

General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, brown
Order No.	2525200000
Type	H0,14/12 BR
GTIN (EAN)	4050118536867
Qty.	500 items

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.03 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Version	Standard
---------	----------

Wire-end ferrules

Contact surface length (L2)	8 mm	L1 in mm	12.00 mm
Wire connection cross section AWG, max.	AWG 26	Stripping length	10 mm
Conductor cross-section	0.14 mm ²		

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		