

## H0,14/12 BR


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

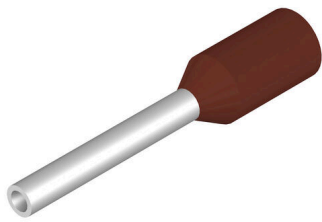

- Weidmüller colour code
- in multipack bag ( 5 x 100 pcs.)

### General ordering data

Version	Wire-end ferrule, Standard, 10 mm, 8 mm, brown
Order No.	<a href="#">2525200000</a>
Type	H0,14/12 BR
GTIN (EAN)	4050118536867
Qty.	500 items

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate no. (cULus)	E499744

**Dimensions and weights**

Net weight	0.03 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Technical data**

Version	Standard
---------	----------

**Wire-end ferrules**

Contact surface length (L2)	8 mm	L1 in mm	12.00 mm
Wire connection cross section AWG, max.	AWG 26	Stripping length	10 mm
Conductor cross-section	0.14 mm <sup>2</sup>		

**Classifications**

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		