


EL 100 MM GN 30M**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

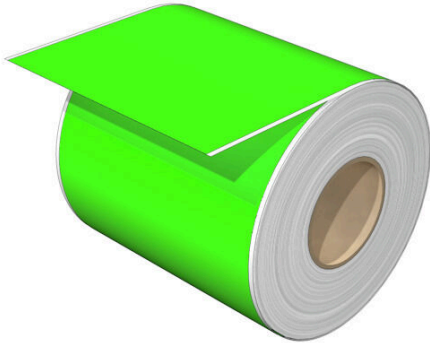

Customised identification: EL

The endless variations of MultiMark markers make them an economical alternative to conventional tag rails or special labels. For any given width, the height can be precisely configured by the software to match the respective markers perfectly. A blade is used to cut the labels individually to the specified size. Perfect for producing large labels for function blocks or complete terminal blocks.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

Version	THM, Device markers, 100 x , green
Order No.	2528370000
Type	EL 100 MM GN 30M
GTIN (EAN)	4050118539264
Qty.	1 items

EL 100 MM GN 30M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.1 mm	Depth (inches)	0.0039 inch
Height	100 mm	Height (inches)	3.937 inch
Length	30000 mm	Length (inches)	1181.1 inch
Net weight	844 g		

Temperatures

Operating temperature range	-40...120 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Adhesive	Acrylate adhesive	Version	halogen-free, Self-adhesive
UL 94 flammability rating	V-0	Operating temperature range, max.	120 °C
Operating temperature range, min.	-40 °C	Colour	green
Halogen	No	Length	30000 mm
Basic material	Polyester	Printed characters	without
Approval acc. to UL 969	Yes	compatible printer	THM MULTIMARK , THM MULTIMARK PLUS
Operating temperature range	-40...120 °C	Number per roll	1


Device markers

Halogen	No
---------	----

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

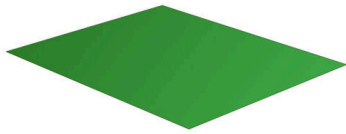

EL 100 MM GN 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/360 SW	Version	
Order No.	2005070000	Ink ribbon	
GTIN (EAN)	4050118390049		
Qty.	1 ST		

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP EXT.RH	Version	
Order No.	1302920000		
GTIN (EAN)	4050118102307		
Qty.	1 ST		
Type	MULTIMARK ROLLER 115	Version	
Order No.	1357420000		
GTIN (EAN)	4050118160314		
Qty.	1 ST		

THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

EL 100 MM GN 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version
Order No.	2672590000	
GTIN (EAN)	4050118708097	
Qty.	1 ST	

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM 110/300 WS	Version
Order No.	2918800000	Ink ribbon
GTIN (EAN)	4099986574878	
Qty.	1 ST	