 


**CH20M17 S PPP AGY 3747****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Product image**

The side element of the CH20M housing offers you the option of an individual structure that can be flexibly adapted to your needs. A particularly practical advantage is that slots that are not required can simply be closed with covers. This not only ensures a clean and tidy appearance, but also protects against dust and other environmental influences. Take advantage of the versatility of the CH20M housing to design your projects efficiently and according to your ideas!

**General ordering data**

Version	Side element, OMNIMATE Housing - series CH20M Agate grey, Side element, Width: 17.5 mm
Order No.	<a href="#">2554700000</a>
Type	CH20M17 S PPP AGY 3747
GTIN (EAN)	4050118565027
Qty.	12 items

## CH20M17 S PPP AGY 3747

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	105.5 mm	Depth (inches)	4.1535 inch
Height	22.8 mm	Height (inches)	0.8976 inch
Width	17.5 mm	Width (inches)	0.689 inch
Net weight	10.75 g		

## Temperatures

Ambient temperature	-25 °C...85 °C	Operating temperature range	-40...120 °C
Humidity	5 - 93% rel. humidity, Tu = 40°C, no condensation		

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

## Material data

UL 94 flammability rating	V-0	Insulating material	PA 66 GF 30
Insulating material group	I	Surface finish	untreated
Basic material	Plastic	Comparative Tracking Index (CTI)	600 ≤ CTI

## General data

Colour	Agate grey	Protection degree	IP20 in installed state
Colour chart (similar)	RAL 7038	Information regarding whole assembly, see referenced articles	<a href="#">CH20M17 B BK/OR 2010</a>
Encapsulation option	No		

## Component properties

Cut out as preparation for functional portNo integrated		Number of poles, max.	9
Number of ventilation openings	0	Number of slots for female plugs	3
Number of connection levels	3		

## Classifications

ETIM 7.0	EC001031	ETIM 8.0	EC001031
ETIM 9.0	EC001031	ETIM 10.0	EC001031
ECLASS 11.0	27-18-27-92	ECLASS 12.0	27-18-27-92
ECLASS 13.0	27-19-06-02	ECLASS 14.0	27-19-06-02
ECLASS 15.0	27-19-06-02		

**CH20M17 S PPP AGY 3747**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**


**Product image**



**Product image**



**Dimensioned drawing**

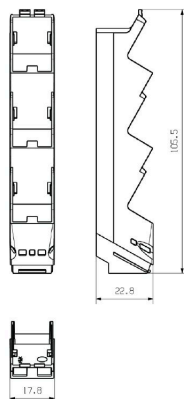

## CH20M17 S PPP AGY 3747

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## CH20M AD SHL 5.00/03 - Side element cover for CH20M17



Future-proof solutions for industrial electronics for mounting in the control cabinet

Electronichousings are crucial for the integration of electronic assemblies in the control cabinet. They protect sensitive components and ensure reliable connections. Thanks to high-quality materials, they offer long-term solutions for industrial applications.

Your advantages:

Flexibility: Scalable solutions for different requirements

Safety: Robust design to protect your electronics

Efficiency: Simple installation and optimized connection technology

Housing solutions for every application:

Our portfolio includes modular housings (e.g. CH20M), small housings and profile housings designed for control, signal conversion and safety applications. These housings offer customizable designs, easy mounting and high connection capacity.

Customization:

In addition to standard solutions, we offer customization in design, color and printing. The Weidmüller Configurator enables individual design.

Our service:

We offer expert advice and technical support for your projects. In the download area you will find CAD data, data sheets and installation instructions for efficient integration.

## General ordering data

Type	CH20M AD SHL 5.00/03 AG...	Version
Order No.	<a href="#">2554740000</a>	Hood, OMNIMATE Housing - series CH20M Agate grey, Side element
GTIN (EAN)	4050118564792	cover, Width: 17.5 mm
Qty.	50 ST	
Type	CH20M AD SHL 5.00/03 BK...	Version
Order No.	<a href="#">1254110000</a>	Hood, OMNIMATE Housing - series CH20M black, Side element
GTIN (EAN)	4050118046922	cover, Width: 17.5 mm
Qty.	50 ST	
Type	CH20M AD SHL 5.00/03 LG...	Version
Order No.	<a href="#">1529540000</a>	Hood, OMNIMATE Housing - series CH20M Light Grey, Side element
GTIN (EAN)	4050118334418	cover, Width: 17.5 mm
Qty.	50 ST	