

**IE-PS-V14M-2SC-POF-QA**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com



PushPull plug-in connector set according to IEC  
61076-3-117 ver.14 (PROFINET), metal incl. SC insert

**General ordering data**

Version	FO connector, Version 14, SC-RJ POF, reconnectable, IP67
Order No.	<a href="#">2568260000</a>
Type	IE-PS-V14M-2SC-POF-QA
GTIN (EAN)	4050118578928
Qty.	10 items

## IE-PS-V14M-2SC-POF-QA

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	79.9 mm	Depth (inches)	3.1457 inch
Height	26.8 mm	Height (inches)	1.0551 inch
Width	22.7 mm	Width (inches)	0.8937 inch
Net weight	55.44 g		

### Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

### Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

### General data

Description of article	Version 14, SC-RJ POF, reconnectable	Colour	Miscellaneous
Housing main material	Zinc diecast	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm	Protection degree	IP67
Plugging cycles	750	Fibre type	POF
Insertion loss	≤ 1.0 dB	Connection 1	SCRJ
Connection 2	Rapid connection system: screwing, cutting	Housing material, insert	PA, Zinc diecast

### General standards

Connector standard	IEC 61076-3-117 Var. 14, IEC 61754-24
--------------------	--

### Classifications

ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		

## IE-PS-V14M-2SC-POF-QA

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## ...for fibre-optic cable with polymer optic fibres (POF)



Crimping and stripping tools for processing the fibre-optic-cable contacts of polymer optical fibres (POF)

## General ordering data

Type	HTX-IE-POF-QA	Version	
Order No.	<a href="#">2602860000</a>		
GTIN (EAN)	4050118615043		
Qty.	1 ST		

## Tools



- For flexible and solid conductors with special insulating materials
- High-quality stripping for industrial applications (complies with aircraft industry requirements)
- Specially shaped blades enable stripping of special types of insulation and conductor configurations
- Stripping length adjustable via end stop
- Very versatile thanks to interchangeable stripping units
- Stripping results reproduced accurately over and over again
- No damage to the conductor
- A long-lasting, reliable tool thanks to its sturdy design
- Integrated cutting function

## General ordering data

Type	MULTI-STRIPAX IE-POF	Version	
Order No.	<a href="#">1208880000</a>	Tools, Stripping and cutting tool	
GTIN (EAN)	4032248990276		
Qty.	1 ST		

## Scissors



Weidmüller is a specialist in the cutting of copper or aluminium cables. The range of products extends from cutters for small cross-sections with direct force application right up to cutters for large diameters. The mechanical operation and the specially designed cutter shape minimise the effort required. With its wide range of cutting products, Weidmüller meets all the criteria for professional cable processing.

## IE-PS-V14M-2SC-POF-QA

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## General ordering data

Type	SCISSORS KEVLAR	Version	
Order No.	<a href="#">1208910000</a>	Electrician's scissors	
GTIN (EAN)	4032248990085		
Qty.	1 ST		

## Dust caps




For protecting your devices against dust and dirt.

## General ordering data

Type	IE-PP-V14P	Version	
Order No.	<a href="#">1058280000</a>	Plug housing protective cap	
GTIN (EAN)	4032248799374		
Qty.	10 ST		

## Blank

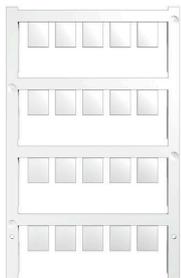

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 9/11 K MC NE WS	Version	
Order No.	<a href="#">1857440000</a>	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive	
GTIN (EAN)	4032248402731		
Qty.	200 ST		