


## VT-TM 1/18 HF-V0

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

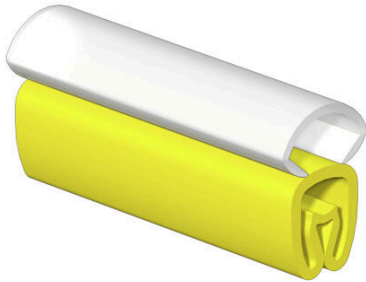

### General ordering data

Version	, Socket x 5.3 mm, Polyester, TPU, Colour: yellow, Transparent, Conductor O.D.: 2.5 - 5 mm
Order No.	<a href="#">2571300000</a>
Type	VT-TM 1/18 HF-V0
GTIN (EAN)	4050118608380
Qty.	200 items

## VT-TM 1/18 HF-V0

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	8.2 mm	Depth (inches)	0.3228 inch
Height	18 mm	Height (inches)	0.7087 inch
Width	5.3 mm	Width (inches)	0.2087 inch
Net weight	0.21 g		

### Temperatures

Operating temperature range	-30...90 °C
-----------------------------	-------------

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Type of printing	neutral	Width	5.3 mm
UL 94 flammability rating	V-0	Operating temperature range, max.	90 °C
Operating temperature range, min.	-30 °C	Colour	yellow, Transparent
Halogen	No	Basic material	Polyester, TPU
Printed characters	without	Recommended industries	Transportation, Machinery
Operating temperature range	-30...90 °C		

### Conductor and cable markers

Halogen	No	Conductor cross-section, max.	1.5 mm <sup>2</sup>
Conductor cross-section, min.	0.5 mm <sup>2</sup>	Conductor O.D., max.	5 mm
Conductor O.D., min.	2.5 mm	Conductor O.D.	2.5 - 5 mm
Cross-section for connected wire	0.5 - 1.5 mm <sup>2</sup>		

### Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		