


VT-TM 2/12 HF-V0

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

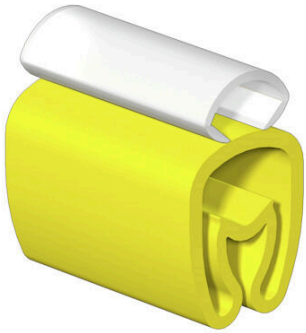

General ordering data

Version	x 5.3 mm, TPU, Colour: yellow, Transparent
Order No.	2571310000
Type	VT-TM 2/12 HF-V0
GTIN (EAN)	4050118608373
Qty.	100 items

VT-TM 2/12 HF-V0

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	12 mm	Height (inches)	0.4724 inch
Width	5.3 mm	Width (inches)	0.2087 inch
Net weight	0.41 g		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Type of printing	neutral	Width	5.3 mm
UL 94 flammability rating	V-0	Operating temperature range, max.	90 °C
Operating temperature range, min.	-30 °C	Colour	yellow, Transparent
Halogen	No	Basic material	TPU
Printed characters	without		

Conductor and cable markers

Halogen	No	Conductor cross-section, max.	2.5 mm ²
Conductor cross-section, min.	0.75 mm ²	Conductor O.D., max.	4 mm
Conductor O.D., min.	2.5 mm		

Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		