


**VT-TM 3/12 HF-V0**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

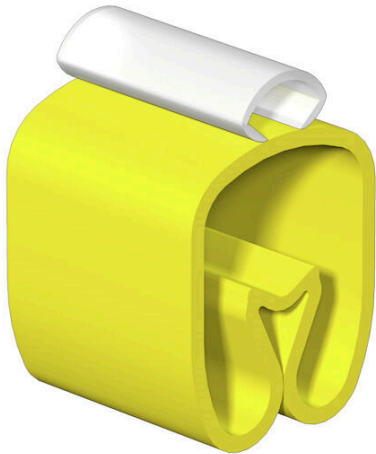

**General ordering data**

Version	x 5.3 mm, TPU, Colour: yellow, Transparent
Order No.	<a href="#">2571330000</a>
Type	VT-TM 3/12 HF-V0
GTIN (EAN)	4050118608359
Qty.	50 items

## VT-TM 3/12 HF-V0

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Height	12 mm	Height (inches)	0.4724 inch
Width	5.3 mm	Width (inches)	0.2087 inch
Net weight	0.71 g		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Type of printing	neutral	Width	5.3 mm
UL 94 flammability rating	V-0	Operating temperature range, max.	90 °C
Operating temperature range, min.	-30 °C	Colour	yellow, Transparent
Halogen	No	Basic material	TPU
Printed characters	without		

### Conductor and cable markers

Halogen	No	Conductor cross-section, max.	6 mm <sup>2</sup>
Conductor cross-section, min.	2.5 mm <sup>2</sup>	Conductor O.D., max.	16 mm
Conductor O.D., min.	8 mm		

### Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		