


DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Product image

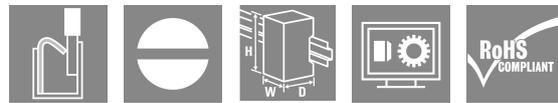

Similar to illustration

- Mounted kit consisting relay, socket and retaining clip
- 100 % function tested
- 100 % check of the dielectric strenght between input - output
- 4 CO contacts
- With mechanical status indicator
- Optional Test button with coloured identification of coils (AC red / DC blue)
- Bright status LED (AC coil: red / DC coil: green)

General ordering data

| | |
|------------|--|
| Version | D-SERIES DRM, Relay module, Number of contacts: 4, CO contact AgNi flash gold-plated, Rated control voltage: 115 V AC, Continuous current: 5 A, PUSH IN, Test button available: No |
| Order No. | 2576010000 |
| Type | DRMKITP 115VAC 4CO LD |
| GTIN (EAN) | 4050118585766 |
| Qty. | 10 items |

DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Depth | 82.3 mm | Depth (inches) | 3.2402 inch |
| Height | 101.8 mm | Height (inches) | 4.0079 inch |
| Width | 30.6 mm | Width (inches) | 1.2047 inch |
| Net weight | 108.2 g | | |

Temperatures

| | | | |
|-----------------------|----------------|---------------------|--|
| Storage temperature | -40 °C...70 °C | Ambient temperature | -40 °C...55 °C |
| Operating temperature | | Humidity | 35...85 % rel. humidity, no condensation |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Control side

| | | | |
|-----------------------|--------------------|------------------|----------------------------------|
| Rated control voltage | 115 V AC | Rated current AC | 12.6 mA (50 Hz), 10.8 mA (60 Hz) |
| Power rating | 1.0...1.2VA (60HZ) | Coil resistance | 4340 Ω ± 10 % |
| Status indicator | red LED | | |

Load side

| | | | |
|---|---------------------------|---|---------------------------------------|
| Rated switching voltage | 250 V AC | Continuous current | 5 A |
| Max. switching frequency at rated load | 0.1 Hz | Max. switching voltage, AC | 250 V |
| Inrush current | 10 A / 50 ms | AC switching capacity (resistive), max. | 1250 VA |
| DC switching capacity (resistive), max. | 120 W @ 24 V | Switch-on delay | <20 ms |
| Switch-off delay | <20 ms | Contact type | 4 CO contact (AgNi flash gold-plated) |
| Mechanical service life | 20 x 106 switching cycles | Min. switching power | 10 mA @ 12 V, 100 mA @ 5 V |

General data

| | | |
|--------------------------------------|--------------------------|---------------|
| Mounting rail | TS 35 | |
| Test button available | No | |
| Mechanical switch position indicator | Yes | |
| Colour | black | |
| UL94 flammability rating component | Component | Housing |
| | UL94 flammability rating | V-2 |
| | Component | Pusher |
| | UL94 flammability rating | HB |
| | Component | Mounting foot |
| | UL94 flammability rating | HB |
| Component | Retaining clip | |

DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

| | |
|--------------------------|------------------------|
| UL94 flammability rating | HB |
| Component | Relay cover |
| UL94 flammability rating | V-2 |
| Component | Relay baseplate |
| UL94 flammability rating | V-0 |
| Component | Relay status indicator |
| UL94 flammability rating | HB |
| Component | Relay test button |
| UL94 flammability rating | HB |

Insulation coordination

| | | | |
|---|-----------------|--|--------------------|
| Rated voltage | 250 V | Pollution severity | 2 |
| Surge voltage category | III | Insulating material group | C |
| Clearance and creepage distances for control side - load side | ≥ 3 mm | Dielectric strength for control side - load side | 1.8 kVeff / 1 min. |
| Dielectric strength of neighbouring contacts | 1 kVeff / 1 min | Dielectric strength of open contact | 1 kVeff / 1 min |
| Protection degree | IP20 | | |

Further details of approvals / standards

| | | | |
|-------------------------------|----------------------------|------------------------------|---------------------------|
| Relevant relay | DRM570615L | Relevant base | SCM 4CO P |
| Certificate no. (cURus) relay | E312083 | Certificate no. (cURus) base | E355547 |

Connection data

| | | | |
|---|---------------------|---|----------------------|
| Wire connection method | PUSH IN | Stripping length, rated connection | 10 mm |
| Clamping range, rated connection | 1.5 mm ² | Clamping range, min. | 0.14 mm ² |
| Clamping range, max. | 1.5 mm ² | Wire connection cross section AWG, min. | AWG 26 |
| Wire connection cross section AWG, max. | AWG 16 | Wire cross-section, solid, min. | 0.14 mm ² |
| Wire cross-section, solid, max. | 1.5 mm ² | Wire connection cross section, finely stranded, min. | 0.14 mm ² |
| Wire connection cross section, finely stranded, max. | 1.5 mm ² | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.14 mm ² |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 1 mm ² | Conductor cross-section, flexible, AEH (DIN 46228-1), min. | 0.14 mm ² |
| Conductor cross-section, flexible, AEH (DIN 46228-1), max. | 1.5 mm ² | Blade size | 0.4 x 2.5 mm |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001437 | ETIM 9.0 | EC001437 |
| ETIM 10.0 | EC001437 | ECLASS 14.0 | 27-37-16-01 |
| ECLASS 15.0 | 27-37-16-01 | | |


DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Drawings

Wiring diagram

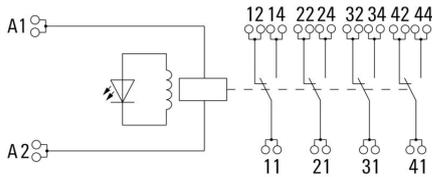


Graph

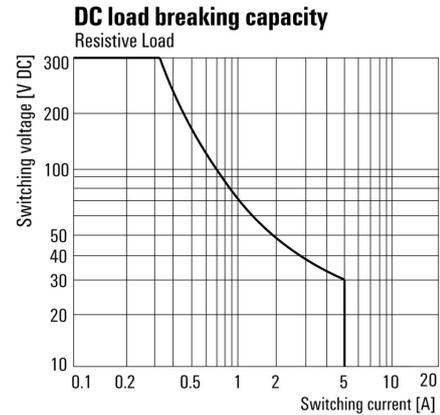


DC load limit curve Resistive load

Graph

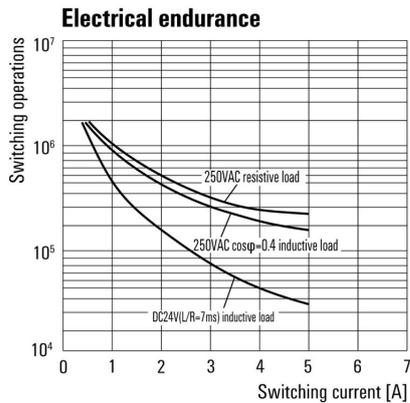


Electrical service life

Graph

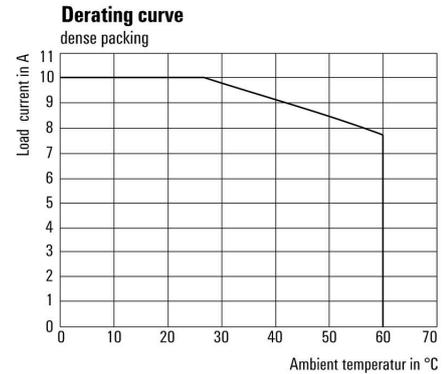


Derating curve

Graph

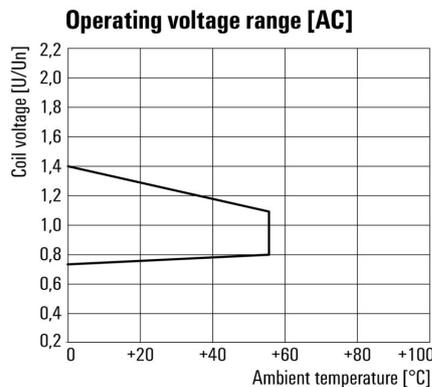

AC operational voltage range

Dimensional drawing

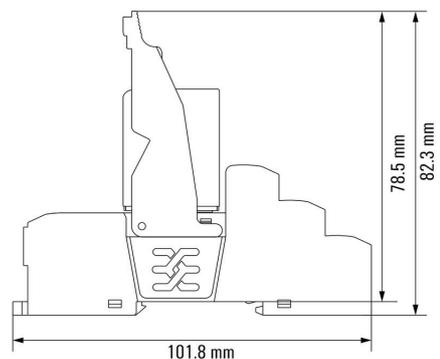

Relay in combination with base


DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Drawings

www.weidmueller.com

Miscellaneous

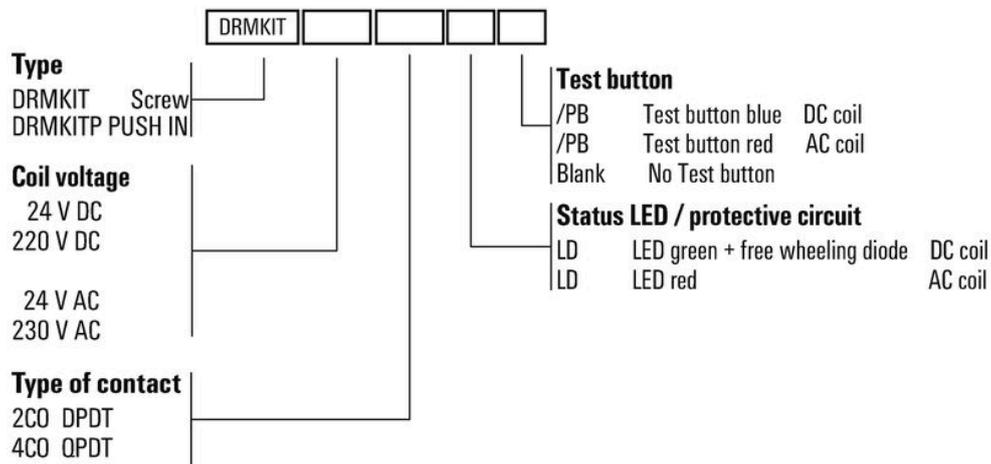

Type codes

DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

LED



Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.

- With green LED

General ordering data

| | | | |
|------------|----------------------------|--|--|
| Type | RIM 3 110/230VUC | Version | |
| Order No. | 7940018455 | D-SERIES, LED module, Rated control voltage: 110...230 V UC, Plug- | |
| GTIN (EAN) | 4032248878185 | in connection | |
| Qty. | 10 ST | | |

Protection modules



Pluggable protective modules for the D-SERIES relay sockets, with optional protective functions.


- With free-wheeling diode or RC filter

General ordering data

| | | | |
|------------|----------------------------|---|--|
| Type | RIM 3 110/230VAC | Version | |
| Order No. | 7760056014 | D-SERIES, RC filter, Rated control voltage: 110...230 V AC, Plug-in | |
| GTIN (EAN) | 4032248878109 | connection | |
| Qty. | 10 ST | | |
| Type | RIM 3 110/230VAC LED | Version | |
| Order No. | 7760056045 | D-SERIES, RC filter, Rated control voltage: 110...230 V AC, Plug-in | |
| GTIN (EAN) | 4032248878147 | connection | |
| Qty. | 10 ST | | |

Cross-connection for socket with PUSH IN connection

Cross-connection for the sockets in the D-SERIES DRM.

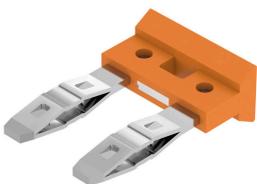

DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Accessories

General ordering data

| | | | |
|------------|----------------------------|---------------------------|--|
| Type | SCM/SDI P CC | Version | |
| Order No. | 7760056366 | D-SERIES, Cross-connector | |
| GTIN (EAN) | 6944 169773327 | | |
| Qty. | 10 ST | | |

Retaining clips

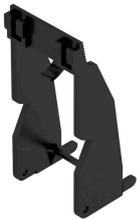


Retaining clip for D-SERIES DRM relays
 • Metal and plastic retaining clip

General ordering data

| | | | |
|------------|----------------------------|--------------------------|--|
| Type | DRM/DRL CLIP M | Version | |
| Order No. | 7760056108 | D-SERIES, Retaining clip | |
| GTIN (EAN) | 4032248855568 | | |
| Qty. | 10 ST | | |

Blank

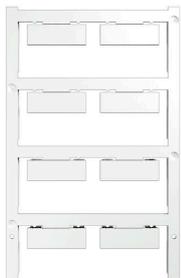

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | | |
|------------|----------------------------|--|--|
| Type | ESG 9/26 SCM ECO MC NE ... | Version | |
| Order No. | 1520980000 | ESG, Device markers x 26 mm, PA 66, Colour: white, pluggable | |
| GTIN (EAN) | 4050118327939 | | |
| Qty. | 80 ST | | |

| | | | |
|------------|----------------------------|---|--|
| Type | ESG 9/26 SCM ECO MC NE ... | Version | |
| Order No. | 1520990000 | ESG, Device markers x 26 mm, PA 66, Colour: yellow, pluggable | |
| GTIN (EAN) | 4050118327861 | | |
| Qty. | 80 ST | | |

DRMKITP 115VAC 4CO LD


Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

| | | |
|------------|----------------------------|---|
| Type | ESG 9/26 SCM ECO MC NE ... | Version |
| Order No. | 152100000 | ESG, Device markers x 26 mm, PA 66, Colour: grey, pluggable |
| GTIN (EAN) | 4050118327878 | |
| Qty. | 80 ST | |

Custom printing

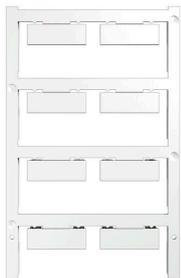

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|---------------------------|--|
| Type | ESG 9/26 SCM ECO MC SDR | Version |
| Order No. | 152580000 | ESG, Device markers x 26 mm, PA 66, Colour: To customer specification, pluggable |
| GTIN (EAN) | 4050118331875 | |
| Qty. | 16 ST | |

Slotted screwdriver



VDE insulated slot-head screwdriver, SDI DIN 7437, ISO 2380/2, drive output acc. to DIN 5264, ISO 2380/1. SoftFinish grip

General ordering data

| | | |
|------------|---------------------------|--|
| Type | SDIS 0.4X2.5X75 | Version |
| Order No. | 274979000 | Screwdriver, Blade width (B): 2.5 mm, Blade length: 75 mm, Blade thickness (A): 0.4 mm |
| GTIN (EAN) | 4050118896534 | |
| Qty. | 1 ST | |
| Type | SDS 0.4X2.5X75 | Version |
| Order No. | 274932000 | Screwdriver, Blade width (B): 2.5 mm, Blade length: 75 mm, Blade thickness (A): 0.4 mm |
| GTIN (EAN) | 4050118895544 | |
| Qty. | 1 ST | |

DRMKITP 115VAC 4CO LD

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

ESG 6/15



Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- "Different materials for various requirements"
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | | | |
|------------|----------------------------|---------------------------------------|--|
| Type | ESG 6/15 MM WS | Version | |
| Order No. | 2619940000 | ESG, Device markers, 6 x 15 mm, white | |
| GTIN (EAN) | 4050118626148 | | |
| Qty. | 3000 ST | | |

ESG 6/17



Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- "Different materials for various requirements"
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | | | |
|------------|----------------------------|---------------------------------------|--|
| Type | ESG 6/17 MM WS | Version | |
| Order No. | 2005100000 | ESG, Device markers, 6 x 17 mm, white | |
| GTIN (EAN) | 4050118390728 | | |
| Qty. | 3000 ST | | |