


ES APG80 WM 400

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

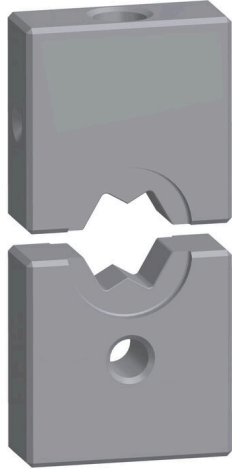

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm²
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
 - electronic control and monitoring of the crimping process
 - Saving of all crimping cycles and error messages to internal memory
 - Reading of all cycles and error messages via USB

General ordering data

| | |
|------------|-------------------------------|
| Version | 400mm ² , WM crimp |
| Order No. | 2578060000 |
| Type | ES APG80 WM 400 |
| GTIN (EAN) | 4064675018124 |
| Qty. | 1 items |

ES APG80 WM 400

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | |
|------------|------|
| Net weight | 70 g |
|------------|------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

Crimp inserts

| | | | |
|----------------------|------|----------------------------|-----|
| Crimping width | 7 mm | Crimp cross-section copper | 400 |
| Crimping width in mm | 7 | | |

Description of contact

| | | | |
|-----------------------------------|-----|----------------------|---------------------|
| Conductor cross-section, max. AWG | 750 | Crimping range, max. | 400 mm ² |
|-----------------------------------|-----|----------------------|---------------------|

tool data crimping

| | |
|-----------------------|----------|
| Crimping type/profile | WM crimp |
|-----------------------|----------|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001282 | ETIM 9.0 | EC001282 |
| ETIM 10.0 | EC001282 | ECLASS 14.0 | 21-04-90-90 |
| ECLASS 15.0 | 21-04-90-90 | | |