

SCHT 7 BG

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration



The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw.

The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

Inlay tags and protective strips can be found under "Accessories".

General ordering data

| | |
|------------|-----------------------------------------------------------------|
| Version | SCHT, Terminal marker, 39.3 x 8 mm, Pitch in mm (P): 7.00 beige |
| Order No. | 2593450000 |
| Type | SCHT 7 BG |
| GTIN (EAN) | 4050118605709 |
| Qty. | 20 items |

SCHT 7 BG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Height | 39.3 mm | Height (inches) | 1.5472 inch |
| Width | 8 mm | Width (inches) | 0.315 inch |
| Net weight | 0.45 g | | |

Temperatures

Operating temperature range -40...100 °C

Environmental Product Compliance

RoHS Compliance Status Compliant
 REACH SVHC No SVHC above 0.1 wt%

General data

| | | | |
|--------------------------------------|------------------------------------|----------------|--|
| Orientation of print | horizontal and vertical | | |
| Width | 8 mm | | |
| UL 94 flammability rating | V-2 | | |
| Operating temperature range, max. | 100 °C | | |
| Operating temperature range, min. | -40 °C | | |
| Colour | beige | | |
| Basic material | Polyamide 66 | | |
| Number of markers per packaging unit | Form of supply | Component part | |
| Number of markers per combination | 1 Component part = Terminal marker | | |
| Operating temperature range | -40...100 °C | | |

Connector markers

Pitch in mm (P) 7.00 mm

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC002848 | ETIM 9.0 | EC002848 |
| ETIM 10.0 | EC002848 | ECLASS 14.0 | 27-14-11-92 |
| ECLASS 15.0 | 27-14-11-92 | | |

SCHT 7 BG

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
 - Strips for fast installation
 - Terminal markers, suitable for all Weidmüller cable connectors
 - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | | |
|------------|----------------------------|-----------------------------------------------------------|--|
| Type | DEK 5/5 MC NE WS | Version | |
| Order No. | 1609801044 | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00 | |
| GTIN (EAN) | 4008190397111 | Weidmueller, white | |
| Qty. | 1000 ST | | |

STR transparent strips



General ordering data

| | | | |
|------------|----------------------------|------------------------------------------------------------|--|
| Type | STR 7 F.SCHT 7 | Version | |
| Order No. | 0515300000 | Terminal markers, Protective cap, 27 x 6.3 mm, Transparent | |
| GTIN (EAN) | 4008190182175 | | |
| Qty. | 20 ST | | |

ESO insert tags



SCHT 7 BG

Weidmüller Interface GmbH & Co. KG

 Klingenbergstraße 26
 D-32758 Detmold
 Germany


www.weidmueller.com

Accessories

General ordering data

| | | |
|------------|----------------------------|-------------------------------------------------------|
| Type | ESO 7 DIN A4 WS | Version |
| Order No. | 1607720000 | Terminal markers, Insert markers, 30 x 6.3 mm, white |
| GTIN (EAN) | 4008190206116 | |
| Qty. | 10 ST | |
| Type | ESO 7 P DIN A4 GE | Version |
| Order No. | 1670400000 | Terminal markers, Insert markers, 27 x 6.3 mm, yellow |
| GTIN (EAN) | 4008190430726 | |
| Qty. | 10 ST | |
| Type | ESO 7 P DIN A4 WS | Version |
| Order No. | 1670390000 | Terminal markers, Insert markers, 27 x 6.3 mm, white |
| GTIN (EAN) | 4008190430719 | |
| Qty. | 10 ST | |
| Type | ESO 7 DIN A4 GE | Version |
| Order No. | 1634780000 | Terminal markers, Insert markers, 27 x 6.3 mm, yellow |
| GTIN (EAN) | 4008190273361 | |
| Qty. | 10 ST | |

Blank

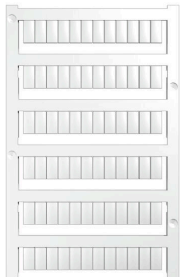

WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with PrintJet CONNECT oder/or Plotter is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | |
|------------|----------------------------|--------------------------------------------------------------------|
| Type | WS 10/5 M MC NE WS | Version |
| Order No. | 1792000000 | WS, Terminal marker, 10 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4032248223862 | Allen-Bradley, white |
| Qty. | 720 ST | |