

THM MULTIMARK

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Version	Marking systems, Thermotransfer printer, Thermal transfer, 300 DPI, MultiMark, Shrink-fit sleeves, Label reel
Order No.	2599430000
Type	THM MULTIMARK
GTIN (EAN)	4050118626377
Qty.	1 items

THM MULTIMARK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Depth	253 mm	Depth (inches)	9.9606 inch
Height	320 mm	Height (inches)	12.5984 inch
Width	253 mm	Width (inches)	9.9606 inch
Net weight	5800 g		

Temperatures

Ambient temperature 5 °C...40 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6aI, 6bI, 6c, 7a, 7cI
REACH SVHC	Lead 7439-92-1
SCIP	7d9d08e1-8ede-49b5-a637-5ea27a383bef

Labelling systems

Marker type	MultiMark, Shrink-fit sleeves, Label reel	Memory (RAM)	256 MB
System requirements	PC with operating system Windows 7, 8 or 10	Printing method	Thermal transfer
Interface	USB 2.0, Ethernet	Software	M-Print® PRO
Supply voltage	100...240 V AC	Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10, Windows 11
Printing speed	max. 150 mm/s	Print resolution, max.	300 DPI
Operation with rechargeable batteries	No	Download	M-Print PRO
Included in delivery	THM MultiMark, Manual, USB cable, Mains cable, Euro plug, US plug, UK plug, Printer driver, RIBBON MM-TB 25/360 SW ink ribbon, RIBBON MM 110/360 SW ink ribbon, Ink ribbon core, Print roller, Pressure roller		

Classifications

ETIM 8.0	EC000610	ETIM 9.0	EC000610
ETIM 10.0	EC000610	ECLASS 14.0	24-32-11-90
ECLASS 15.0	24-32-11-90		


THM MULTIMARK

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

THM MULTIMARK

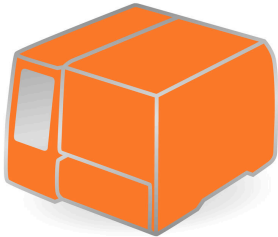

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	THM MMP CASE	Version
Order No.	2457760000	Empty box / Case
GTIN (EAN)	4050118473131	
Qty.	1 ST	
Type	MULTIMARK CUTTER	Version
Order No.	1331600000	Cutting kit
GTIN (EAN)	4050118163155	
Qty.	1 ST	
Type	MULTIMARK PERFORATOR	Version
Order No.	1416330000	Cutting kit
GTIN (EAN)	4050118219388	
Qty.	1 ST	
Type	THM MMP EXT.RH	Version
Order No.	1302920000	
GTIN (EAN)	4050118102307	
Qty.	1 ST	
Type	MULTIMARK ROLLER 115	Version
Order No.	1357420000	
GTIN (EAN)	4050118160314	
Qty.	1 ST	
Type	MULTIMARK ROLLER 30	Version
Order No.	1357430000	
GTIN (EAN)	4050118160253	
Qty.	1 ST	
Type	MULTIMARK ROLLER MF	Version
Order No.	2518600000	
GTIN (EAN)	4050118531305	
Qty.	1 ST	
Type	MULTIMARK ROLLER MF-W	Version
Order No.	2519150000	
GTIN (EAN)	4050118531091	
Qty.	1 ST	
Type	MULTIMARK ROLLER SFM 1	Version
Order No.	2799000000	
GTIN (EAN)	4064675259985	
Qty.	1 ST	
Type	MULTIMARK ROLLER SFM 2	Version
Order No.	2786210000	
GTIN (EAN)	4064675063230	
Qty.	1 ST	

THM MULTIMARK

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Type	MULTIMARK ROLLER SFM 3	Version
Order No.	2719270000	
GTIN (EAN)	4050118849158	
Qty.	1 ST	
Type	MULTIMARK ROLLER SFM 4	Version
Order No.	2835010000	
GTIN (EAN)	4064675427346	
Qty.	1 ST	
Type	MULTIMARK ROLLER TB	Version
Order No.	2438500000	
GTIN (EAN)	4050118498721	
Qty.	1 ST	

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-TB 25/360 SW	Version
Order No.	2005090000	Ink ribbon
GTIN (EAN)	4050118390216	
Qty.	1 ST	
Type	RIBBON MM-HS 60/300 SW	Version
Order No.	2448880000	Ink ribbon
GTIN (EAN)	4050118462944	
Qty.	1 ST	
Type	RIBBON MM 76/360 SW	Version
Order No.	2005080000	Ink ribbon
GTIN (EAN)	4050118389951	
Qty.	1 ST	
Type	RIBBON MM 84/300 WS	Version
Order No.	2005040000	Ink ribbon
GTIN (EAN)	4050118390025	
Qty.	1 ST	
Type	RIBBON MM 110/360 SW	Version
Order No.	2005070000	Ink ribbon
GTIN (EAN)	4050118390049	
Qty.	1 ST	
Type	RIBBON HSS HF EL 40/300...	Version
Order No.	1426210000	Ink ribbon
GTIN (EAN)	4050118228823	
Qty.	1 ST	

M-Print® PRO



The M-Print® PRO printing and ordering software for markers and labels® is a professional Windows®-based solution for both printing and ordering Weidmüller labels and markers. This software allows you to optimise the process of identifying electrical equipment. You can design and order your marking materials easily, professionally and quickly: with text, frames, lines, graphics, bar codes, serial numbers and photos.

- Integrated product catalogue for all labels and markers, incl. images, link to the website and product data sheet
- Markers and labels can be designed on as many levels as required
- Customised formatting of individual text characters (RTF)
- Copy and paste texts and their formats
- Available in 20 languages supporting UNICODE
- Data entry in labels and spreadsheets, or directly in Microsoft Excel
- Creation of scales; numeric and alpha-numeric counters and sequences
- Extensive range of image formats (*.bmp, *.wmf, *.png, *.ico, *.jpeg, *.jpg, *.tif, *.gif)
- Image library including symbols used in electrical engineering
- Product-printer allocation options, e.g. ESG 9/20 to PrintJet; MultiMark on thermotransfer printer
- Online update service via the Internet
- Weidmueller Configurator (WMC) interface
- Import wizard for a number of file formats (*.txt, *.csv, *.xml, etc.) for creating your own import scripts
- Transfer of data from CAE systems
- Permanent print preview: see what the printout will look like even at the design phase, WYSIWYG editing
- Supported output devices: All Weidmueller printers (e.g. PrintJet CONNECT, THM MultiMark, etc.) and standard printers with Microsoft Windows® driver
- Optimal and fast adaptation of output devices
- Multi-level structuring of markers and labels

General ordering data

Type	M-PRINT PRO	Version
Order No.	1905490000	Software for markings, Software, Windows 10, Windows 11, Printer
GTIN (EAN)	4032248526291	software
Qty.	1 ST	