

**THM MULTIMARK PLUS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Version	Marking systems, Thermotransfer printer, Thermal transfer, 300 DPI, MultiMark, Shrink-fit sleeves, Label reel
Order No.	<a href="#">2599440000</a>
Type	THM MULTIMARK PLUS
GTIN (EAN)	4050118626360
Qty.	1 items

**THM MULTIMARK PLUS**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS Conform

**Dimensions and weights**

Depth	274 mm	Depth (inches)	10.7874 inch
Height	446 mm	Height (inches)	17.559 inch
Width	242 mm	Width (inches)	9.5275 inch
Net weight	10000 g		

**Temperatures**

Ambient temperature 5 °C...40 °C

**Environmental Product Compliance**

RoHS Compliance Status	Compliant
REACH SVHC	Lead 7439-92-1
SCIP	7d9d08e1-8ede-49b5-a637-5ea27a383bef

**Labelling systems**

Marker type	MultiMark, Shrink-fit sleeves, Label reel	System requirements	PC with operating system Windows 7, 8 or 10
Printing method	Thermal transfer	Interface	USB 2.0, Ethernet
Software	M-Print® PRO	Supply voltage	100...240 V AC
Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10, Windows 11	Printing speed	max. 150 mm/s
Print resolution, max.	300 DPI	Operation with rechargeable batteries	No
Download	M-Print PRO	Included in delivery	THM MultiMark, USB cable, Mains cable, Euro plug, US plug, UK plug, Printer driver, RIBBON MM-TB 25/360 SW ink ribbon, RIBBON MM 110/360 SW ink ribbon, Ink ribbon core, Print roller, Pressure roller, W-LAN stick

**Classifications**

ETIM 8.0	EC000610	ETIM 9.0	EC000610
ETIM 10.0	EC000610	ECLASS 14.0	24-32-11-90
ECLASS 15.0	24-32-11-90		


**THM MULTIMARK PLUS**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Accessories**

**THM MULTIMARK PLUS**

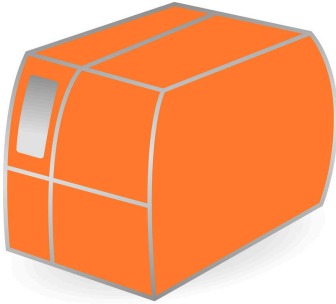

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MULTIMARK PLUS ROLLER MF	Version
Order No.	<a href="#">2661610000</a>	
GTIN (EAN)	4050118681222	
Qty.	1 ST	
Type	MULTIMARK PLUS ROLLER M...	Version
Order No.	<a href="#">2661620000</a>	
GTIN (EAN)	4050118681239	
Qty.	1 ST	
Type	MULTIMARK PLUS ROLLER TB	Version
Order No.	<a href="#">2661600000</a>	
GTIN (EAN)	4050118681246	
Qty.	1 ST	
Type	MULTIMARK PLUS PERFORAT...	Version
Order No.	<a href="#">1540770000</a>	Cutting kit
GTIN (EAN)	4050118345711	
Qty.	1 ST	

## THM MULTIMARK PLUS

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

## Accessories

www.weidmueller.com

## M-Print® PRO



The M-Print® PRO printing and ordering software for markers and labels® is a professional Windows®-based solution for both printing and ordering Weidmüller labels and markers . This software allows you to optimise the process of identifying electrical equipment. You can design and order your marking materials easily, professionally and quickly: with text, frames, lines, graphics, bar codes, serial numbers and photos.

- Integrated product catalogue for all labels and markers, incl. images, link to the website and product data sheet
- Markers and labels can be designed on as many levels as required
- Customised formatting of individual text characters (RTF)
- Copy and paste texts and their formats
- Available in 20 languages supporting UNICODE
- Data entry in labels and spreadsheets, or directly in Microsoft Excel
- Creation of scales; numeric and alpha-numeric counters and sequences
- Extensive range of image formats (\*.bmp, \*.wmf, \*.png, \*.ico, \*.jpeg, \*.jpg, \*.tif, \*.gif)
- Image library including symbols used in electrical engineering
- Product-printer allocation options, e.g. ESG 9/20 to PrintJet; MultiMark on thermotransfer printer
- Online update service via the Internet
- Weidmueller Configurator (WMC) interface
- Import wizard for a number of file formats (\*.txt, \*.csv, \*.xml, etc.) for creating your own import scripts
- Transfer of data from CAE systems
- Permanent print preview: see what the printout will look like even at the design phase, WYSIWYG editing
- Supported output devices: All Weidmueller printers (e.g. PrintJet CONNECT, THM MultiMark, etc.) and standard printers with Microsoft Windows® driver
- Optimal and fast adaptation of output devices
- Multi-level structuring of markers and labels

## General ordering data

Type	M-PRINT PRO	Version
Order No.	<a href="#">1905490000</a>	Software for markings, Software, Windows 10, Windows 11, Printer
GTIN (EAN)	4032248526291	software
Qty.	1 ST	

**THM MULTIMARK PLUS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Accessories**

**THM MULTIMARK PLUS**



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	<a href="#">2672590000</a>		
GTIN (EAN)	4050118708097		
Qty.	1 ST		