

THM MULTIMARK PLUS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Version	Marking systems, Thermotransfer printer, Thermal transfer, 300 DPI, MultiMark, Shrink-fit sleeves, Label reel
Order No.	2599440000
Type	THM MULTIMARK PLUS
GTIN (EAN)	4050118626360
Qty.	1 items

THM MULTIMARK PLUS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Depth	274 mm	Depth (inches)	10.7874 inch
Height	446 mm	Height (inches)	17.559 inch
Width	242 mm	Width (inches)	9.5275 inch
Net weight	10000 g		

Temperatures

Ambient temperature 5 °C...40 °C

Environmental Product Compliance

RoHS Compliance Status	Compliant
REACH SVHC	Lead 7439-92-1
SCIP	7d9d08e1-8ede-49b5-a637-5ea27a383bef

Labelling systems

Marker type	MultiMark, Shrink-fit sleeves, Label reel	System requirements	PC with operating system Windows 7, 8 or 10
Printing method	Thermal transfer	Interface	USB 2.0, Ethernet
Software	M-Print® PRO	Supply voltage	100...240 V AC
Operating system	Windows 7, Windows 8, Windows 8.1, Windows 10, Windows 11	Printing speed	max. 150 mm/s
Print resolution, max.	300 DPI	Operation with rechargeable batteries	No
Included in delivery	THM MultiMark, USB cable, Mains cable, Euro plug, US plug, UK plug, Printer driver, RIBBON MM-TB 25/360 SW ink ribbon, RIBBON MM 110/360 SW ink ribbon, Ink ribbon core, Print roller, Pressure roller, W-LAN stick		

Classifications

ETIM 8.0	EC000610	ETIM 9.0	EC000610
ETIM 10.0	EC000610	ECLASS 14.0	24-32-11-90
ECLASS 15.0	24-32-11-90		


THM MULTIMARK PLUS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

THM MULTIMARK PLUS

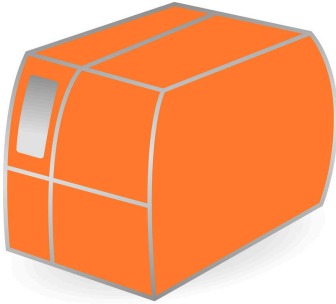

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK PLUS ROLLER MF	Version
Order No.	2661610000	
GTIN (EAN)	4050118681222	
Qty.	1 ST	
Type	MULTIMARK PLUS ROLLER M...	Version
Order No.	2661620000	
GTIN (EAN)	4050118681239	
Qty.	1 ST	
Type	MULTIMARK PLUS ROLLER TB	Version
Order No.	2661600000	
GTIN (EAN)	4050118681246	
Qty.	1 ST	
Type	MULTIMARK PLUS PERFORAT...	Version
Order No.	1540770000	Cutting kit
GTIN (EAN)	4050118345711	
Qty.	1 ST	

THM MULTIMARK PLUS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

M-Print® PRO



The M-Print® PRO printing and ordering software for markers and labels® is a professional Windows®-based solution for both printing and ordering Weidmüller labels and markers . This software allows you to optimise the process of identifying electrical equipment. You can design and order your marking materials easily, professionally and quickly: with text, frames, lines, graphics, bar codes, serial numbers and photos.

- Integrated product catalogue for all labels and markers, incl. images, link to the website and product data sheet
- Markers and labels can be designed on as many levels as required
- Customised formatting of individual text characters (RTF)
- Copy and paste texts and their formats
- Available in 20 languages supporting UNICODE
- Data entry in labels and spreadsheets, or directly in Microsoft Excel
- Creation of scales; numeric and alpha-numeric counters and sequences
- Extensive range of image formats (*.bmp, *.wmf, *.png, *.ico, *.jpeg, *.jpg, *.tif, *.gif)
- Image library including symbols used in electrical engineering
- Product-printer allocation options, e.g. ESG 9/20 to PrintJet; MultiMark on thermotransfer printer
- Online update service via the Internet
- Weidmueller Configurator (WMC) interface
- Import wizard for a number of file formats (*.txt, *.csv, *.xml, etc.) for creating your own import scripts
- Transfer of data from CAE systems
- Permanent print preview: see what the printout will look like even at the design phase, WYSIWYG editing
- Supported output devices: All Weidmueller printers (e.g. PrintJet CONNECT, THM MultiMark, etc.) and standard printers with Microsoft Windows® driver
- Optimal and fast adaptation of output devices
- Multi-level structuring of markers and labels

General ordering data

Type	M-PRINT PRO	Version
Order No.	1905490000	Software for markings, Software, Windows 10, Windows 11, Printer
GTIN (EAN)	4032248526291	software
Qty.	1 ST	