


H0,5/16S OR BD GSP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration

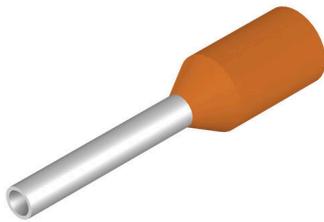

- Linked wire-end ferrules on reel (5,000 pcs.)
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 12 mm, 10 mm, orange
Order No.	2604620000
Type	H0,5/16S OR BD GSP
GTIN (EAN)	4050118649420
Qty.	4000 items

H0,5/16S OR BD GSP

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate No. (UR)	E354986

Dimensions and weights

Net weight	0.11 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Reel of wire end ferrules, orange	Version	Standard
------------------------	--------------------------------------	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	1 mm	Contact surface length (L2)	10 mm
Collar diameter (D2)	2.9 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	16.00 mm	Wire connection cross section AWG, max.	AWG 20
Metal sleeve thickness (S1)	0.15 mm	Stripping length	12 mm
Conductor cross-section	0.5 mm ²	Colour code	Weidmueller

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

