

**ESG-FO 8/20 MM WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

**General ordering data**

|            |                                       |
|------------|---------------------------------------|
| Version    | ESG, Device markers, 8 x 20 mm, white |
| Order No.  | <a href="#">2620950000</a>            |
| Type       | ESG-FO 8/20 MM WS                     |
| GTIN (EAN) | 4050118626032                         |
| Qty.       | 1000 items                            |

## ESG-FO 8/20 MM WS

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 0.55 mm | Depth (inches)  | 0.0217 inch |
| Height     | 8 mm    | Height (inches) | 0.315 inch  |
| Width      | 20 mm   | Width (inches)  | 0.7874 inch |
| Net weight | 0.05 g  |                 |             |

## Temperatures

|                             |             |
|-----------------------------|-------------|
| Operating temperature range | -30...80 °C |
|-----------------------------|-------------|

## Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

## General data

|                                   |                                                                    |                                   |                             |
|-----------------------------------|--------------------------------------------------------------------|-----------------------------------|-----------------------------|
| Adhesive                          | PE-foam with acrylic adhesive                                      | Version                           | Self-adhesive, halogen-free |
| Width                             | 20 mm                                                              | UL 94 flammability rating         | V-0                         |
| Operating temperature range, max. | 80 °C                                                              | Operating temperature range, min. | -30 °C                      |
| Colour                            | white                                                              | Halogen                           | No                          |
| Basic material                    | Polyester                                                          | Printed characters                | without                     |
| Size of labelling field           | 8 x 20 mm                                                          | Approval acc. to UL 969           | Yes                         |
| compatible printer                | <a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a> | Operating temperature range       | -30...80 °C                 |
| Number per roll                   | 1000                                                               |                                   |                             |

## Device markers

|         |    |
|---------|----|
| Halogen | No |
|---------|----|

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001288    | ETIM 9.0    | EC001288    |
| ETIM 10.0   | EC001288    | ECLASS 14.0 | 27-28-11-04 |
| ECLASS 15.0 | 27-28-11-04 |             |             |



**ESG-FO 8/20 MM WS****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Accessories****Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

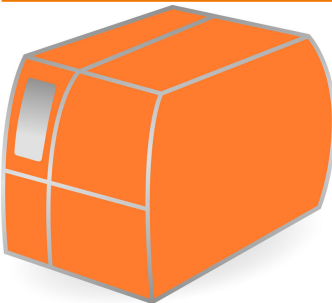
|            |                            |            |  |
|------------|----------------------------|------------|--|
| Type       | RIBBON MM 76/360 SW        | Version    |  |
| Order No.  | <a href="#">2005080000</a> | Ink ribbon |  |
| GTIN (EAN) | 4050118389951              |            |  |
| Qty.       | 1 ST                       |            |  |

**THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | MULTIMARK ROLLER 115       | Version |  |
| Order No.  | <a href="#">1357420000</a> |         |  |
| GTIN (EAN) | 4050118160314              |         |  |
| Qty.       | 1 ST                       |         |  |

**THM MULTIMARK PLUS**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | MULTIMARK PLUS ROLLER 1... | Version |  |
| Order No.  | <a href="#">2672590000</a> |         |  |
| GTIN (EAN) | 4050118708097              |         |  |
| Qty.       | 1 ST                       |         |  |