


CC-FO 30/60 MM WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

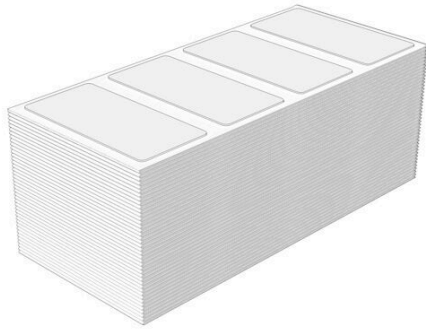

Standard included: CC

Our systematically matching product range includes labels for identifying standardised components, as well as all-purpose and familiar formats such as the CC 85/54 marker for nameplates.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | |
|------------|---|
| Version | ClipCard, Device markers, 30 x 60 mm, white |
| Order No. | 2621280000 |
| Type | CC-FO 30/60 MM WS |
| GTIN (EAN) | 4050118625769 |
| Qty. | 100 items |

CC-FO 30/60 MM WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 0.55 mm | Depth (inches) | 0.0217 inch |
| Height | 30 mm | Height (inches) | 1.1811 inch |
| Width | 60 mm | Width (inches) | 2.3622 inch |
| Net weight | 1.55 g | | |

Temperatures

| | |
|-----------------------------|-------------|
| Operating temperature range | -30...80 °C |
|-----------------------------|-------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | | |
|-----------------------------------|--|-----------------------------------|-----------------------------|
| Adhesive | PE-foam with acrylic adhesive | Version | Self-adhesive, halogen-free |
| Width | 60 mm | UL 94 flammability rating | V-0 |
| Operating temperature range, max. | 80 °C | Operating temperature range, min. | -30 °C |
| Colour | white | Halogen | No |
| Basic material | Polyester | Printed characters | without |
| Size of labelling field | 30 x 60 mm | Approval acc. to UL 969 | Yes |
| compatible printer | THM MULTIMARK , THM MULTIMARK PLUS | Operating temperature range | -30...80 °C |
| Number per roll | 100 | | |

Device markers

| | |
|---------|----|
| Halogen | No |
|---------|----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ETIM 10.0 | EC001288 | ECLASS 14.0 | 27-28-11-04 |
| ECLASS 15.0 | 27-28-11-04 | | |

Drawings

