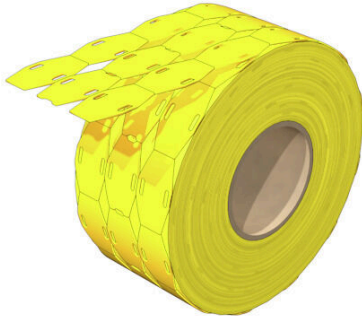


SFX-VT 9/24 MM GE**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

**Highly flexible: SFX**

SFX markers are the preferred choice for labelling cables if you prefer the classic cable tie solution. Cables do not always run in a straight line. The material used in SFX markers addresses this fact with highly flexible polyurethane. The marker follows each curve of the cable and latches on with ease. Your advantages at a glance: Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours

Individually labeled with the M-Print® PRO

Easy and fast printing with the THM MultiMark

General ordering data

Version	SlimFix, Conductor and cable markers, 7 -, 26 x 15 mm, yellow
Order No.	2621460000
Type	SFX-VT 9/24 MM GE
GTIN (EAN)	4050118625585
Qty.	1000 items

SFX-VT 9/24 MM GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	26 mm	Height (inches)	1.0236 inch
Width	15 mm	Width (inches)	0.5906 inch
Net weight	0.2 g		

Temperatures

Operating temperature range	-55...105 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Type of printing	neutral	Version	halogen-free
Width	15 mm	UL 94 flammability rating	HB
Operating temperature range, max.	105 °C	Operating temperature range, min.	-55 °C
Colour	yellow	Halogen	No
Basic material	Polyolefine, Polyurethane	Printed characters	without
Size of labelling field	23.5 x 9 mm	compatible printer	THM MULTIMARK , THM MULTIMARK PLUS
Operating temperature range	-55...105 °C		

Conductor and cable markers

Halogen	No	Conductor cross-section, max.	500 mm ²
Conductor O.D., max.	40 mm	Conductor O.D., min.	7 mm
Cable tie passage	Flat	Conductor O.D.	7 -
Suitable cable tie	Plastic	Cross-section for connected wire	500 mm ²

Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		

Drawings



SFX-VT 9/24 MM GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	RIBBON MM-HS 60/300 SW	Version	
Order No.	2448880000	Ink ribbon	
GTIN (EAN)	4050118462944		
Qty.	1 ST		

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK ROLLER 115	Version	
Order No.	1357420000		
GTIN (EAN)	4050118160314		
Qty.	1 ST		

THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	2672590000		
GTIN (EAN)	4050118708097		
Qty.	1 ST		