

SFX-DT 9/24 MM BL


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

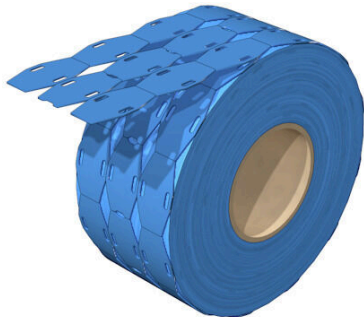

We support our customers in the food industry with detectable marking solutions to ensure the high standards required within the framework of the HACCP concept. Thanks to a metallic filler, our detectable Multi-Mark markers can be reliably identified by metal and X-ray detectors. This minimises the risk of product contamination in the production process. Maximum safety is ensured with important product properties, such as corrosion resistance or higher ageing resistance to UV radiation in indoor areas and heat. These properties are regularly tested and confirmed in our own accredited laboratory. Not suitable for direct food contact. • Detectable by metal and X-ray detectors

- Visually recognisable by blue colour
- Corrosion resistant metallic filler
- Clear and resistant print image
- Available in different versions for a wide variety of marking requirements

Highly flexible: SFX

SFX markers are the preferred choice for labelling cables if you prefer the classic cable tie solution. Cables do not always run in a straight line. The material used in SFX markers addresses this fact with highly flexible polyurethane. The marker follows each curve of the cable and latches on with ease.

General ordering data

| | |
|------------|---|
| Version | SlimFix, Conductor and cable markers, 7 -, 26 x 15 mm, blue |
| Order No. | 2621490000 |
| Type | SFX-DT 9/24 MM BL |
| GTIN (EAN) | 4050118625554 |
| Qty. | 1000 items |

SFX-DT 9/24 MM BL

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|-------|-----------------|-------------|
| Height | 26 mm | Height (inches) | 1.0236 inch |
| Width | 15 mm | Width (inches) | 0.5906 inch |
| Net weight | 0.2 g | | |

Temperatures

| | | | |
|----------------------------------|-------------|----------------------------------|--------|
| Operating temperature range | -30...65 °C | Continuous operating temp., min. | -30 °C |
| Continuous operating temp., max. | 65 °C | | |

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | | |
|-----------------------------------|--------------|-----------------------------------|--|
| Type of printing | neutral | Version | halogen-free |
| Width | 15 mm | UL 94 flammability rating | HB |
| Operating temperature range, max. | 65 °C | Operating temperature range, min. | -30 °C |
| Colour | blue | Halogen | No |
| Basic material | Polyethylene | Printed characters | without |
| Size of labelling field | 23.5 x 9 mm | compatible printer | THM MULTIMARK , THM MULTIMARK PLUS |
| Operating temperature range | -30...65 °C | Number per roll | 1000 |

Conductor and cable markers

| | | | |
|----------------------|---------|----------------------------------|---------------------|
| Halogen | No | Conductor cross-section, max. | 500 mm ² |
| Conductor O.D., max. | 40 mm | Conductor O.D., min. | 7 mm |
| Cable tie passage | Flat | Conductor O.D. | 7 - |
| Suitable cable tie | Plastic | Cross-section for connected wire | 500 mm ² |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ETIM 10.0 | EC001530 | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 | | |

SFX-DT 9/24 MM BL

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON MM-HS 60/300 SW | Version | |
| Order No. | 2448880000 | Ink ribbon | |
| GTIN (EAN) | 4050118462944 | | |
| Qty. | 1 ST | | |

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | MULTIMARK ROLLER 115 | Version | |
| Order No. | 1357420000 | | |
| GTIN (EAN) | 4050118160314 | | |
| Qty. | 1 ST | | |

THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | MULTIMARK PLUS ROLLER 1... | Version | |
| Order No. | 2672590000 | | |
| GTIN (EAN) | 4050118708097 | | |
| Qty. | 1 ST | | |