


**THM WO 25/37 WS**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

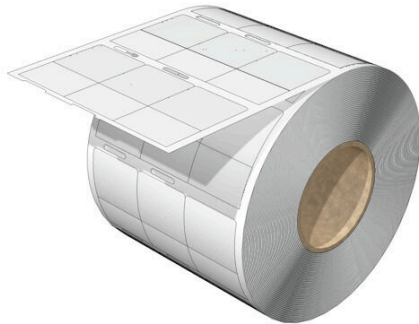

THM WriteOn cable markers on reels are used for labelling conductors and cables with an outside diameter of up to 36 mm. The transparent adhesive strip fixes and protects the printing on the marker surface.

- Protection of the marking against dirt and abrasion by wrapping it with the transparent adhesive strip
- Simple and quick printing with the high-quality thermal transfer printers

**General ordering data**

|            |   |
|------------|---|
| Version    | THM, Conductor and cable markers, 4.8 - 7 mm, 25 x 37 mm, white |
| Order No.  | <a href="#">2621510000</a>                                      |
| Type       | THM WO 25/37 WS   |
| GTIN (EAN) | 4050118625530   |
| Qty.       | 2500 items  |

**THM WO 25/37 WS**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 0.03 mm | Depth (inches)  | 0.001 inch  |
| Height     | 25 mm   | Height (inches) | 0.9842 inch |
| Width      | 37 mm   | Width (inches)  | 1.4567 inch |
| Net weight | 0.16 g  |                 |             |

**Temperatures**

Operating temperature range -40...

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

|                                      |  |            |  |
|--------------------------------------|--|------------|--|
| Type of printing                     | neutral  |            |  |
| Version                              | Self-adhesive  |            |  |
| Width                                | 37 mm  |            |  |
| UL 94 flammability rating            | V-0  |            |  |
| Operating temperature range, min.    | -40 °C   |            |  |
| Colour                               | white  |            |  |
| Halogen                              | No   |            |  |
| Printed characters                   | without  |            |  |
| Number of markers per packaging unit | Form of supply   | Label reel |  |
| Size of labelling field              | 15 x 25 mm   |            |  |
| compatible printer                   | <a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a> |            |  |
| Number of markers per combination    | 1 Label reel = Conductor and cable markers                         |            |  |
| Operating temperature range          | -40...   |            |  |
| Number per roll                      | 2500   |            |  |

**Conductor and cable markers**

|                      |        |                      |            |
|----------------------|--------|----------------------|------------|
| Halogen              | No     | Conductor O.D., max. | 7 mm       |
| Conductor O.D., min. | 4.8 mm | Conductor O.D.       | 4.8 - 7 mm |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001288    | ETIM 9.0    | EC001288    |
| ETIM 10.0   | EC001288    | ECLASS 14.0 | 27-28-11-04 |
| ECLASS 15.0 | 27-28-11-04 |             |             |

