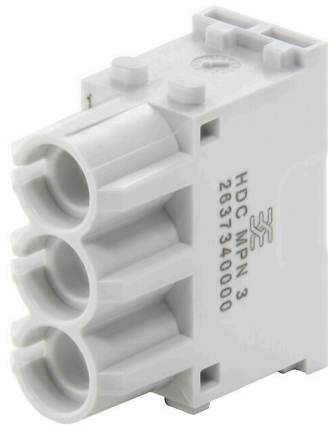


HDC MPN 3**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Flexible**

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

General ordering data

Version	Pneumatic module, Number of poles: 3, Hose connection (pneumatic), pneumatic, Required plug-in slots: 1
Order No.	2637340000
Type	HDC MPN 3
GTIN (EAN)	4050118765823
Qty.	1 items

HDC MPN 3

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Net weight	6.6 g
------------	-------

Temperatures

Limit temperature	-40 °C ... 80 °C
-------------------	------------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	Potassium perfluorobutane sulfonate 29420-49-3
SCIP	1609748e-c278-4c9b-b3d1-e6215d2988cd

General data

Number of poles	3	UL 94 flammability rating	V-0
Plugging cycles	≥ 500	Type	pneumatic
Basic material	Polycarbonate, glass fibre reinforced	Series	ModuPlug
Required plug-in slots	1		

Pneumatic module

Module operating pressure	8 bar	Inner hose diameter, min.	1.6 mm
Inner hose diameter, max.	4 mm		

Version

Type of connection	Hose connection (pneumatic)	Conductor cross-section, max.	0 mm ²
Conductor cross-section, min.	0 mm ²		

Classifications

ETIM 8.0	EC000438	ETIM 9.0	EC000438
ETIM 10.0	EC000438	ECLASS 14.0	27-44-02-20
ECLASS 15.0	27-44-02-20		

Drawings

