


SAKTR 4/ZZ STB RE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

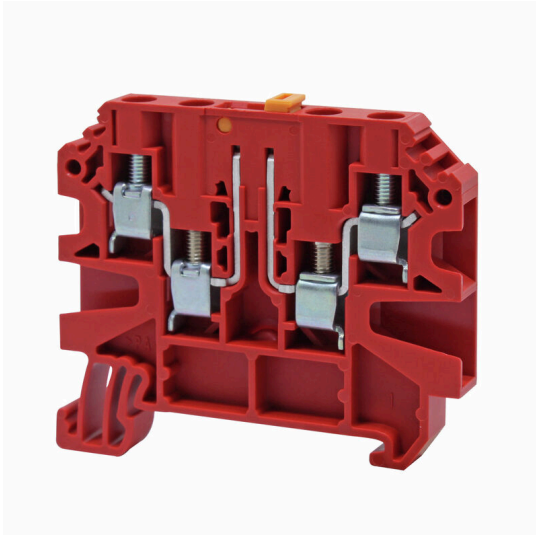

General ordering data

Version	Test-disconnect terminal, Screw connection, red, 4 mm ² , Number of connections: 4, Number of levels: 1
Order No.	2657450000
Type	SAKTR 4/ZZ STB RE
GTIN (EAN)	4050118706161
Qty.	50 items

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Net weight 11.1 g

Environmental Product Compliance

RoHS Compliance Status Compliant with exemption
 RoHS Exemption (if applicable/known) 6c
 REACH SVHC Lead 7439-92-1
 SCIP 999cd67e-471e-4085-8dba-1342fcea86de

Material data

Colour red UL 94 flammability rating V-0

System specifications

Number of potentials 1 Number of levels 1

Conductors for clamping (rated connection)

Wire connection cross section AWG, max.	AWG 10	Type of connection	Screw connection
Number of connections	4	Clamping range, max.	6 mm ²
Clamping range, min.	0.5 mm ²	Wire connection cross section AWG, min.	AWG 26

General

Wire connection cross section AWG, max. AWG 10 Wire connection cross section AWG, min. AWG 26

Rating data

Rated cross-section 4 mm²

Classifications

ETIM 8.0	EC000902	ETIM 9.0	EC000902
ETIM 10.0	EC000902	ECLASS 14.0	27-25-01-09
ECLASS 15.0	27-25-01-09		