


## CB-HTR 365/7,5 NC

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

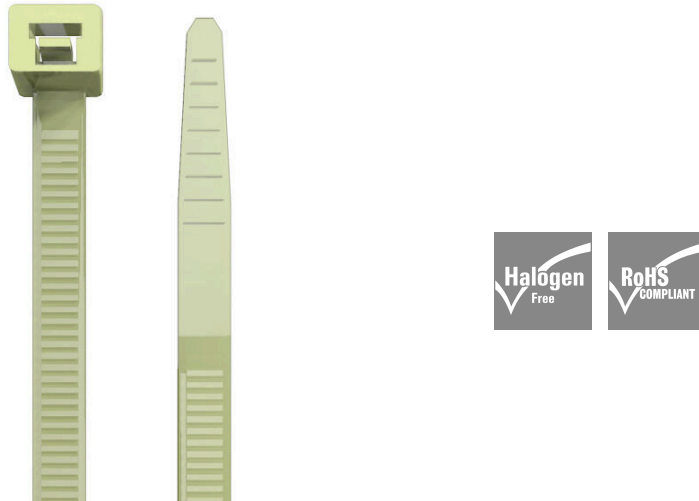

Our heat-stabilised cable ties made of polyamide 6.6 are suitable for continuous use at temperatures up to +125°C.

### General ordering data

|            |   |
|------------|---|
| Version    | Cable ties, 7.5 x 365 mm, Polyamide 66, 540 N |
| Order No.  | <a href="#">2659480000</a>                    |
| Type       | CB-HTR 365/7,5 NC                             |
| GTIN (EAN) | 4050118682946                                 |
| Qty.       | 100 items                                     |

**CB-HTR 365/7,5 NC**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS Conform

**Dimensions and weights**

|            |        |                 |              |
|------------|--------|-----------------|--------------|
| Depth      | 1 mm   | Depth (inches)  | 0.0394 inch  |
| Height     | 365 mm | Height (inches) | 14.3701 inch |
| Width      | 7.5 mm | Width (inches)  | 0.2953 inch  |
| Net weight | 4.21 g |                 |              |

**Temperatures**

|                                  |              |                                  |        |
|----------------------------------|--------------|----------------------------------|--------|
| Operating temperature range      | -40...125 °C | Continuous operating temp., min. | -40 °C |
| Continuous operating temp., max. | 125 °C       |                                  |        |

**Environmental Product Compliance**

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

**Installation materials**

|                                   |         |                                   |              |
|-----------------------------------|---------|-----------------------------------|--------------|
| UV-resistant                      | No      | For re-opening                    | No           |
| UL 94 flammability rating         | V-2     | Operating temperature range, max. | 125 °C       |
| Operating temperature range, min. | -40 °C  | Halogen                           | No           |
| Cable diameter, max.              | 100 mm  | Basic material                    | Polyamide 66 |
| Tensile strength                  | 540 N   | Bundle diameter, max.             | 100 mm       |
| Tensile strength (Pound-force)    | 121 lbf | Bundle diameter, min.             | 8 mm         |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000046    | ETIM 9.0    | EC000046    |
| ETIM 10.0   | EC000046    | ECLASS 14.0 | 27-14-07-02 |
| ECLASS 15.0 | 27-14-07-02 |             |             |

**Drawings**

