

**HDC MHP 70 FC****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Flexible**

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

**General ordering data**

Version	Power module, 1000 V, 70 A, Number of poles: 2, Crimp connection, Female, Required plug-in slots: 1
Order No.	<a href="#">2668180000</a>
Type	HDC MHP 70 FC
GTIN (EAN)	4050118765892
Qty.	1 items

## HDC MHP 70 FC

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E92202

## Dimensions and weights

Depth	34 mm	Depth (inches)	1.3386 inch
Height	47.95 mm	Height (inches)	1.8878 inch
Width	14.5 mm	Width (inches)	0.5709 inch
Net weight	9.7 g		

## Temperatures

Limit temperature -40 °C ... 125 °C

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	Potassium perfluorobutane sulfonate 29420-49-3
SCIP	1609748e-c278-4c9b-b3d1-e6215d2988cd

## General data

Number of poles	2	UL 94 flammability rating	V-0
Insulation resistance	1012 Ω	Plugging cycles	≥ 500
Type	Female	Surge voltage category	III
Pollution severity	3	Basic material	Polycarbonate, glass fibre reinforced
Series	ModuPlug	Rated voltage (DIN EN 61984)	1000 V
Rated voltage according to UL/CSA	600 V	Rated impulse voltage (DIN EN 61984)	8 kV
Rated current (DIN EN 61984)	70 A	Required plug-in slots	1

## PE connection data

Connection type PE	Screw connection via module frame
--------------------	-----------------------------------


## Version

Stripping length, rated connection	15 mm	Type of connection	Crimp connection
Conductor cross-section, max.	25 mm <sup>2</sup>	Conductor cross-section, min.	6 mm <sup>2</sup>

## Classifications

ETIM 8.0	EC000438	ETIM 9.0	EC000438
ETIM 10.0	EC000438	ECLASS 14.0	27-44-02-17
ECLASS 15.0	27-44-02-17		

Drawings

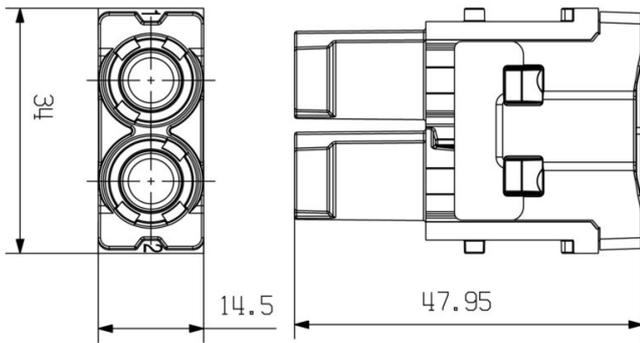

## HDC MHP 70 FC

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### 70 A crimp contacts



Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

### General ordering data

Type	HDC MHP70 F 10	Version
Order No.	<a href="#">2668200000</a>	Female, silver, 10 - 10 mm <sup>2</sup>
GTIN (EAN)	4050118803006	
Qty.	10 ST	
Type	HDC MHP70 F 16	Version
Order No.	<a href="#">2668220000</a>	Female, silver, 16 - 16 mm <sup>2</sup>
GTIN (EAN)	4050118802917	
Qty.	10 ST	
Type	HDC MHP70 F 25	Version
Order No.	<a href="#">2668260000</a>	Female, silver, 25 - 25 mm <sup>2</sup>
GTIN (EAN)	4050118802924	
Qty.	10 ST	
Type	HDC MHP70 F 6	Version
Order No.	<a href="#">2668210000</a>	Female, silver, 6 - 6 mm <sup>2</sup>
GTIN (EAN)	4050118802894	
Qty.	10 ST	

## HDC MHP 70 FC

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

## Counterpart

[www.weidmueller.com](http://www.weidmueller.com)

### Electrical modules



#### Flexible

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

### General ordering data

Type	HDC MHP 70 MAS	Version	
Order No.	<a href="#">2748300000</a>	Power module, 1000 V, 70 A, Number of poles: 2, Axial screw connection, Male, Required plug-in slots: 1	
GTIN (EAN)	4050118891119		
Qty.	2 ST		
Type	HDC MHP 70 MC	Version	
Order No.	<a href="#">2668190000</a>	Power module, 1000 V, 70 A, Number of poles: 2, Crimp connection, Male, Required plug-in slots: 1	
GTIN (EAN)	4050118767537		
Qty.	1 ST		