



The Weidmüller connecting module is helpful whenever you have to repair or want to extend a broken installation cable without cable reserve in confined spaces.

### General ordering data

Version	Connecting module, IP68 (50 m / 24 h)
Order No.	<a href="#">2685560000</a>
Type	IE-CCM-3P-8.5
GTIN (EAN)	4050118695311
Qty.	1 items

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (cURus)	E486077

**Dimensions and weights**

Net weight	35 g
------------	------

**Temperatures**

Storage temperature	Operating temperature	-40 °C...105 °C
Installation temperature		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant
REACH SVHC	No SVHC above 0.1 wt%

**General Info**

Number of poles	3	Colour	black
Housing main material	Nylon, Glass fibre, UL recognized	Contact material	Brass, nickel plated
Contact surface	Nickel-plated CuZn	Wire connection cross section, finely stranded, min.	0.75 mm <sup>2</sup>
Wire connection cross section, finely stranded, max.	3.5 mm <sup>2</sup>	Conductor connection cross-section, flexible	0.75...3.5 mm <sup>2</sup>
Protection degree	IP68 (50 m / 24 h)		

**Electrical properties**

Nominal voltage	600 V	Rated current	20 A
-----------------	-------	---------------	------

**General standards**


Certificate No. (cURus)	E486077
-------------------------	---------

**Classifications**

ETIM 8.0	EC001059	ETIM 9.0	EC001059
ETIM 10.0	EC001059	ECLASS 14.0	27-40-02-12
ECLASS 15.0	27-40-02-12		

Drawings

Dimensioned drawing

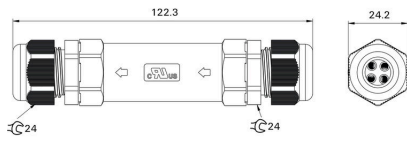

Installation cut-out

