


**SCCB TTB 6/4****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

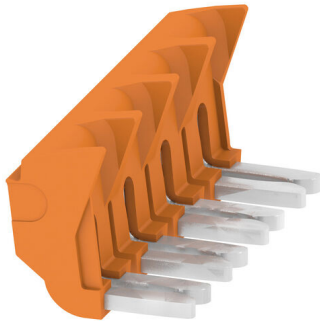

The comprehensive accessories of the Klippon® Connect TTB-Range are perfectly matched down to the last detail. This facilitates mounting while adhering to required norms. All function- and safety-relevant components are captively connected to the terminal block. This increases the reliability of the current and voltage transformer circuits during installation and maintenance work.

**General ordering data**

|            |                                                                                                                              |
|------------|------------------------------------------------------------------------------------------------------------------------------|
| Version    | Cross-connector (terminal), Plugged, orange, 30 A, Number of poles: 4, Pitch in mm (P): 8.10, Insulated: Yes, Width: 32.2 mm |
| Order No.  | <a href="#">2710210000</a>                                                                                                   |
| Type       | SCCB TTB 6/4                                                                                                                 |
| GTIN (EAN) | 4050118848007                                                                                                                |
| Qty.       | 25 items                                                                                                                     |

## Technical data

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Dimensions and weights

|            |          |                 |             |
|------------|----------|-----------------|-------------|
| Depth      | 13.47 mm | Depth (inches)  | 0.5303 inch |
| Height     | 14.06 mm | Height (inches) | 0.5535 inch |
| Width      | 32.2 mm  | Width (inches)  | 1.2677 inch |
| Net weight | 5.6 g    |                 |             |

### Temperatures

|                     |                |
|---------------------|----------------|
| Storage temperature | -25 °C...55 °C |
|---------------------|----------------|

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### Material data

|                |       |        |        |
|----------------|-------|--------|--------|
| Basic material | Wemid | Colour | orange |
|----------------|-------|--------|--------|

### System specifications

|         |                 |
|---------|-----------------|
| Version | Cross-connector |
|---------|-----------------|

### Additional technical data

|                  |         |                          |    |
|------------------|---------|--------------------------|----|
| Type of fixing   | Plugged | Explosion-tested version | No |
| Type of mounting | Plugged |                          |    |

### Dimensions

|                 |         |
|-----------------|---------|
| Pitch in mm (P) | 8.10 mm |
|-----------------|---------|

### General

|                 |   |
|-----------------|---|
| Number of poles | 4 |
|-----------------|---|

### Rating data

|               |       |                 |      |
|---------------|-------|-----------------|------|
| Rated voltage | 500 V | Nominal current | 30 A |
|---------------|-------|-----------------|------|

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000489    | ETIM 9.0    | EC000489    |
| ETIM 10.0   | EC000489    | ECLASS 14.0 | 27-25-03-03 |
| ECLASS 15.0 | 27-25-03-03 |             |             |