


THM WO-Q VIN 25/51.4 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

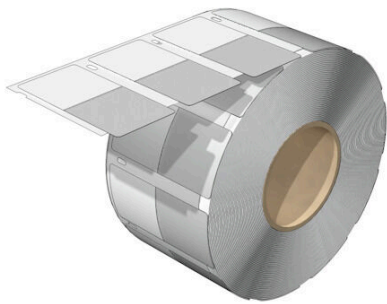

THM WriteOn cable markers on reels are used for labelling conductors and cables with an outside diameter of up to 36 mm. The transparent adhesive strip fixes and protects the printing on the marker surface.

- Protection of the marking against dirt and abrasion by wrapping it with the transparent adhesive strip
- Simple and quick printing with the high-quality thermal transfer printers

General ordering data

| | |
|------------|---|
| Version | THM, Conductor and cable markers, 4.5 - 9 mm, 25 x 51.4 mm, white |
| Order No. | 2711940000 |
| Type | THM WO-Q VIN 25/51.4 WS |
| GTIN (EAN) | 4050118749991 |
| Qty. | 1000 items |

THM WO-Q VIN 25/51.4 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 0.08 mm | Depth (inches) | 0.0031 inch |
| Height | 25 mm | Height (inches) | 0.9842 inch |
| Width | 51.4 mm | Width (inches) | 2.0236 inch |
| Net weight | 0.27 g | | |

Temperatures

| | |
|-----------------------------|-------------|
| Operating temperature range | -40...80 °C |
|-----------------------------|-------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | |
|--------------------------------------|--|------------|
| Adhesive | Polyacrylate adhesive | |
| Orientation of print | horizontal and vertical | |
| Type of printing | neutral | |
| Width | 51.4 mm | |
| UL 94 flammability rating | V-0 | |
| Operating temperature range, max. | 80 °C | |
| Operating temperature range, min. | -40 °C | |
| Colour | white | |
| Halogen | Yes | |
| Basic material | Vinyl film | |
| Printed characters | without | |
| Number of markers per packaging unit | Form of supply | Label reel |
| Approval acc. to UL 969 | Yes | |
| compatible printer | THM MULTIMARK , THM MULTIMARK PLUS | |
| Number of markers per combination | 1 Label reel = Conductor and cable markers | |
| Operating temperature range | -40...80 °C | |
| Number per roll | 1000 | |


Conductor and cable markers

| | | | |
|----------------------|------------|----------------------------------|--------------------|
| Halogen | Yes | Conductor cross-section, max. | 63 mm ² |
| Conductor O.D., max. | 9 mm | Conductor O.D., min. | 4.5 mm |
| Conductor O.D. | 4.5 - 9 mm | Cross-section for connected wire | 63 mm ² |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ETIM 10.0 | EC001530 | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 | | |

 Drawings



THM WO-Q VIN 25/51.4 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON MM 76/360 SW | Version | |
| Order No. | 2005080000 | Ink ribbon | |
| GTIN (EAN) | 4050118389951 | | |
| Qty. | 1 ST | | |
| Type | RIBBON MM 110/360 SW | Version | |
| Order No. | 2005070000 | Ink ribbon | |
| GTIN (EAN) | 4050118390049 | | |
| Qty. | 1 ST | | |