


SFX 11/60 MM BP WS**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

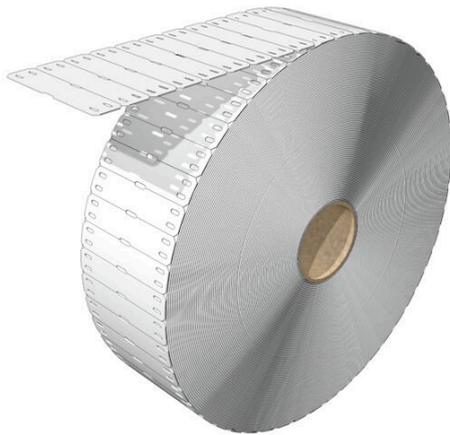**Highly flexible: SFX**

SFX markers are the preferred choice for labelling cables if you prefer the classic cable tie solution. Cables do not always run in a straight line. The material used in SFX markers addresses this fact with highly flexible polyurethane. The marker follows each curve of the cable and latches on with ease.

General ordering data

| | |
|------------|--|
| Version | SlimFix, Conductor and cable markers, 7 - 40 mm, 60 x 13 mm, white |
| Order No. | 2712110000 |
| Type | SFX 11/60 MM BP WS |
| GTIN (EAN) | 4050118749823 |
| Qty. | 6000 items |

SFX 11/60 MM BP WS

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 0.6 mm | Depth (inches) | 0.0236 inch |
| Height | 60 mm | Height (inches) | 2.3622 inch |
| Width | 13 mm | Width (inches) | 0.5118 inch |
| Net weight | 0.55 g | | |

Temperatures

| | |
|-----------------------------|-------------|
| Operating temperature range | -40...90 °C |
|-----------------------------|-------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | | |
|-----------------------------------|--------------|-----------------------------------|--|
| Type of printing | neutral | Version | halogen-free |
| Width | 13 mm | UL 94 flammability rating | HB |
| Operating temperature range, max. | 90 °C | Operating temperature range, min. | -40 °C |
| Colour | white | Halogen | No |
| Basic material | Polyurethane | Printed characters | without |
| Size of labelling field | 44 x 10.5 mm | compatible printer | THM MULTIMARK , THM MULTIMARK PLUS |
| Operating temperature range | -40...90 °C | Number per roll | 1000 |

Conductor and cable markers

| | | | |
|----------------------------------|--------------------------|-------------------------------|---------------------|
| Halogen | No | Conductor cross-section, max. | 500 mm ² |
| Conductor cross-section, min. | 16 mm ² | Conductor O.D., max. | 40 mm |
| Conductor O.D., min. | 7 mm | Text field width | 44 mm |
| Cable tie passage | Flat | Text field height | 10.5 mm |
| Conductor O.D. | 7 - 40 mm | Suitable cable tie | Plastic |
| Cross-section for connected wire | 16 - 500 mm ² | | |

Classifications


| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ETIM 10.0 | EC001530 | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 | | |

SFX 11/60 MM BP WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

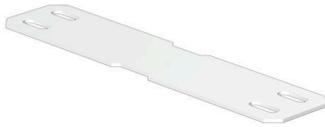

SFX 11/60 MM BP WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Ink ribbons




These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON MM 76/360 SW | Version | |
| Order No. | 2005080000 | Ink ribbon | |
| GTIN (EAN) | 4050118389951 | | |
| Qty. | 1 ST | | |

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON MM 110/360 SW | Version | |
| Order No. | 2005070000 | Ink ribbon | |
| GTIN (EAN) | 4050118390049 | | |
| Qty. | 1 ST | | |

THM MULTIMARK

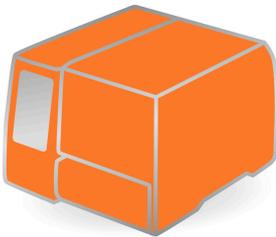

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | THM MMP EXT.RH | Version | |
| Order No. | 1302920000 | | |
| GTIN (EAN) | 4050118102307 | | |
| Qty. | 1 ST | | |