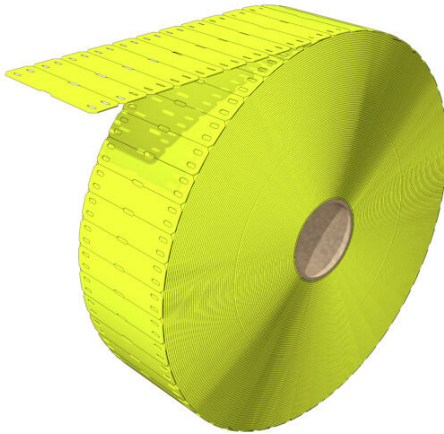


**SFX 11/60 MM BP GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Highly flexible: SFX**

SFX markers are the preferred choice for labelling cables if you prefer the classic cable tie solution. Cables do not always run in a straight line. The material used in SFX markers addresses this fact with highly flexible polyurethane. The marker follows each curve of the cable and latches on with ease.

**General ordering data**

|            |                                                                     |
|------------|---------------------------------------------------------------------|
| Version    | SlimFix, Conductor and cable markers, 7 - 40 mm, 60 x 13 mm, yellow |
| Order No.  | <a href="#">2712120000</a>                                          |
| Type       | SFX 11/60 MM BP GE                                                  |
| GTIN (EAN) | 4050118749816                                                       |
| Qty.       | 6000 items                                                          |

## SFX 11/60 MM BP GE

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

## Dimensions and weights

|            |        |                 |             |
|------------|--------|-----------------|-------------|
| Depth      | 0.6 mm | Depth (inches)  | 0.0236 inch |
| Height     | 60 mm  | Height (inches) | 2.3622 inch |
| Width      | 13 mm  | Width (inches)  | 0.5118 inch |
| Net weight | 0.46 g |                 |             |

## Temperatures

|                             |             |
|-----------------------------|-------------|
| Operating temperature range | -40...90 °C |
|-----------------------------|-------------|

## Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

## General data

|                                   |              |                                   |                                                                    |
|-----------------------------------|--------------|-----------------------------------|--------------------------------------------------------------------|
| Type of printing                  | neutral      | Version                           | halogen-free                                                       |
| Width                             | 13 mm        | UL 94 flammability rating         | HB                                                                 |
| Operating temperature range, max. | 90 °C        | Operating temperature range, min. | -40 °C                                                             |
| Colour                            | yellow       | Halogen                           | No                                                                 |
| Basic material                    | Polyurethane | Printed characters                | without                                                            |
| Size of labelling field           | 44 x 10.5 mm | compatible printer                | <a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a> |
| Operating temperature range       | -40...90 °C  | Number per roll                   | 1000                                                               |

## Conductor and cable markers

|                                  |                          |                               |                     |
|----------------------------------|--------------------------|-------------------------------|---------------------|
| Halogen                          | No                       | Conductor cross-section, max. | 500 mm <sup>2</sup> |
| Conductor cross-section, min.    | 16 mm <sup>2</sup>       | Conductor O.D., max.          | 40 mm               |
| Conductor O.D., min.             | 7 mm                     | Text field width              | 44 mm               |
| Cable tie passage                | Flat                     | Text field height             | 10.5 mm             |
| Conductor O.D.                   | 7 - 40 mm                | Suitable cable tie            | Plastic             |
| Cross-section for connected wire | 16 - 500 mm <sup>2</sup> |                               |                     |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ETIM 10.0   | EC001530    | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 |             |             |

**Drawings**

