

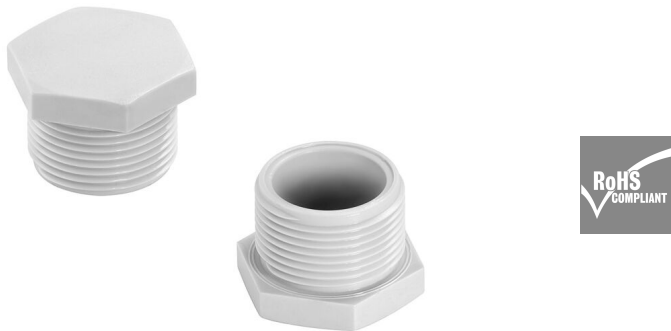
**VP HEX M16 PA6 GY****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

Version	Blanking plugs, in closed state, M 16 x 1.5, 15 mm, Polyamide 6 (PA 6)
Order No.	<a href="#">2715740000</a>
Type	VP HEX M16 PA6 GY
GTIN (EAN)	4050118805093
Qty.	50 items

## VP HEX M16 PA6 GY

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Height	4.3 mm	Height (inches)	0.1693 inch
Width	19 mm	Width (inches)	0.748 inch
Length	15 mm	Length (inches)	0.5906 inch
Diameter	22 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	14 mm	Net weight	0 g

## Temperatures

Operating temperature	-20 °C...100 °C
-----------------------	-----------------

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

## General information

Tightening torque	1.5 Nm	UL 94 flammability rating	V-2
Operating temperature range, max.	100 °C	Operating temperature range, min.	-20 °C
Pitch of thread	1.5 mm	Halogen	No
Standards	in accordance with UL94 V-2	Protection degree	IP65, IP68 - 5 bar (30 min.)
Cable gland	metric	Basic material	Polyamide 6 (PA 6)
Diameter of sealing ring	16.00 mm	External thread	M 16 x 1.5
Length of thread	15 mm		

## Classifications

ETIM 8.0	EC000451	ETIM 9.0	EC000451
ETIM 10.0	EC000451	ECLASS 14.0	27-14-08-05
ECLASS 15.0	27-14-08-05		