

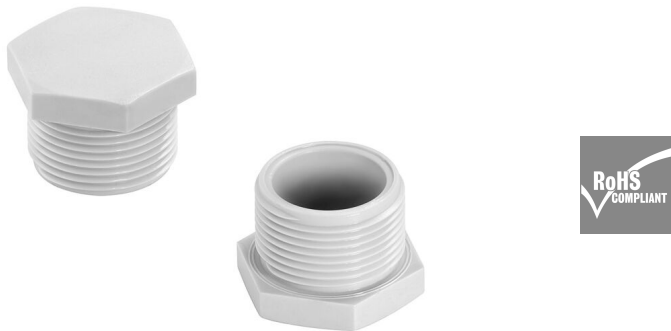
VP HEX M40 PA6 GY**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Similar to illustration

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	Blanking plugs, in closed state, M 40 x 1.5, 18 mm, Polyamide 6 (PA 6)
Order No.	2715780000
Type	VP HEX M40 PA6 GY
GTIN (EAN)	4050118805437
Qty.	10 items

VP HEX M40 PA6 GY

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	8.5 mm	Height (inches)	0.3346 inch
Width	46 mm	Width (inches)	1.811 inch
Length	18 mm	Length (inches)	0.7087 inch
Diameter	53 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	17 mm	Net weight	0.02 g

Temperatures

Operating temperature	-20 °C...100 °C
-----------------------	-----------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General information

Tightening torque	6 Nm	UL 94 flammability rating	V-2
Operating temperature range, max.	100 °C	Operating temperature range, min.	-20 °C
Pitch of thread	1.5 mm	Halogen	No
Standards	in accordance with UL94 V-2	Protection degree	IP65, IP68 - 5 bar (30 min.)
Cable gland	metric	Basic material	Polyamide 6 (PA 6)
Diameter of sealing ring	40.00 mm	External thread	M 40 x 1.5
Length of thread	18 mm		

Classifications

ETIM 8.0	EC000451	ETIM 9.0	EC000451
ETIM 10.0	EC000451	ECLASS 14.0	27-14-08-05
ECLASS 15.0	27-14-08-05		