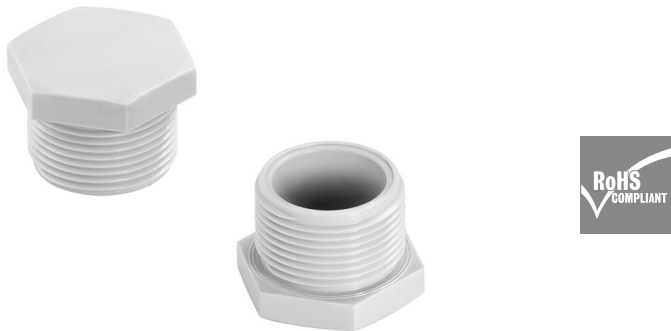


**VP HEX M50 PA6 GY**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

**General ordering data**

Version	Blanking plugs, in closed state, M 50 x 1.5, 18 mm, Polyamide 6 (PA 6)
Order No.	<a href="#">2715790000</a>
Type	VP HEX M50 PA6 GY
GTIN (EAN)	4050118805444
Qty.	10 items

**VP HEX M50 PA6 GY**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Height	9.5 mm	Height (inches)	0.374 inch
Width	55 mm	Width (inches)	2.1654 inch
Length	18 mm	Length (inches)	0.7087 inch
Diameter	63.5 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	17 mm	Net weight	0.04 g

**Temperatures**

Operating temperature -20 °C...100 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General information**

Tightening torque	8 Nm	UL 94 flammability rating	V-2
Operating temperature range, max.	100 °C	Operating temperature range, min.	-20 °C
Pitch of thread	1.5 mm	Halogen	No
Standards	in accordance with UL94 V-2	Protection degree	IP65, IP68 - 5 bar (30 min.)
Cable gland	metric	Basic material	Polyamide 6 (PA 6)
Diameter of sealing ring	50.00 mm	External thread	M 50 x 1.5
Length of thread	18 mm		

**Classifications**

ETIM 8.0	EC000451	ETIM 9.0	EC000451
ETIM 10.0	EC000451	ECLASS 14.0	27-14-08-05
ECLASS 15.0	27-14-08-05		