

**HDC 16B TSS 1M40 WMP****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

Our flange-mounted housings made of plastic have a built-in cable gland and a screw interlock. They seal directly onto the panel wall and can therefore be used without an attachment housing. The housings are impressive with their low weight and optimal protection against contamination, water and vibrations.

**General ordering data**

Version	HDC enclosures, Installation size: 6, Protection degree: IP66, IP67, in plugged condition, Cable entry from side, Screw, , Size of cable entries: M 40
Order No.	<a href="#">2716770000</a>
Type	HDC 16B TSS 1M40 WMP
GTIN (EAN)	4050118803648
Qty.	1 items

**HDC 16B TSS 1M40 WMP**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (cURus)	E223801

**Dimensions and weights**

Height	102 mm	Height (inches)	4.0157 inch
Net weight	175 g		

**Temperatures**

Ambient temperature	-40 °C... 100 °C
---------------------	------------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Cable Gland WMP**

Cable diameter, min.	19 mm	Cable diameter, max.	28 mm
AF size	36 mm	Size of cable entries	M 40

**Dimensions**

Cable entry	w. cable glands	Height of housing B	102 mm
-------------	-----------------	---------------------	--------

**General data**

UL 94 flammability rating	V-0	Surface finish	untreated
Protection degree	IP66, IP67, in plugged condition		

**Version**

Number of cable glands	1	Size of cable entries	M 40
Top part/bottom part/lid	upper part	Cover	without cover
Tightening torque	3 Nm	Number of cable entry sideways	1
Design of housing	Cable entry from side	Design of locking system	Screw
Installation size	6	Cable entry	w. cable glands
Type	Plug	Sealing	NBR
Colour (RAL)	RAL 9011	BG	6
Suitable for ModuPlug®	Yes		

**Classifications**



ETIM 8.0	EC000437	ETIM 9.0	EC000437
ETIM 10.0	EC000437	ECLASS 14.0	27-44-02-02
ECLASS 15.0	27-44-02-02		

**HDC 16B TSS 1M40 WMP**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

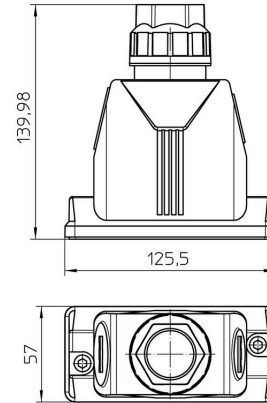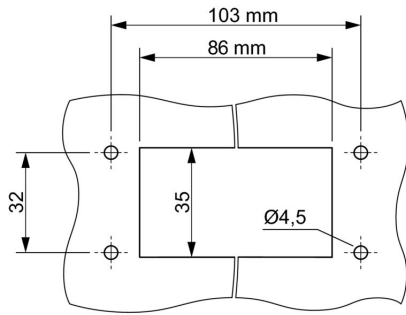

## HDC 16B TSS 1M40 WMP

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

## Accessories

www.weidmueller.com

### Mounting brackets



Our flange-mounted housings made of plastic have a built-in cable gland and a screw interlock. They seal directly onto the panel wall and can therefore be used without an attachment housing. The housings are impressive with their low weight and optimal protection against contamination, water and vibrations.

### General ordering data

Type	HDC AF SET WM	Version
Order No.	<a href="#">2716800000</a>	HDC enclosures, Installation size: , Protection degree:
GTIN (EAN)	4050118803679	
Qty.	1 ST	
Type	HDC AF WM	Version
Order No.	<a href="#">2716790000</a>	HDC enclosures, Installation size: , Protection degree:
GTIN (EAN)	4050118803662	
Qty.	20 ST	