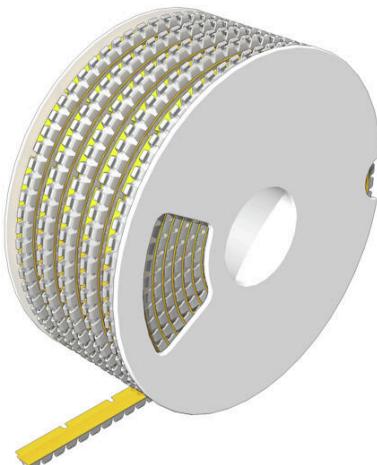


**SFM 4/24 3.3-4.0 MM GE****Weidmüller Interface GmbH & Co. KG**

Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

With the comprehensive MultiMark product family, you can achieve optimally structured and sustainable marking in every control cabinet. An example of this is our new SlimFix wire marker, which can be printed and snapped on particularly quickly. At the same time, they meet the highest requirements for vibration and shock resistance. The wire markers have an open design and can be easily and quickly installed before or after the wiring process.

**General ordering data**

Version	Conductor and cable markers, 2.5 - 4 mm, yellow
Order No.	<a href="#">2719260000</a>
Type	SFM 4/24 3.3-4.0 MM GE
GTIN (EAN)	4050118888294
Qty.	600 items

**SFM 4/24 3.3-4.0 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergsstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Technical data****Approvals**

RoHS	Conform
------	---------

**Dimensions and weights**

Width	5.7 mm	Width (inches)	0.2244 inch
Length	24 mm	Length (inches)	0.9449 inch
Net weight	0.45 g		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**General data**

Orientation of print	horizontal and vertical	Type of printing	neutral
Version	with snap-in foot	Width	5.7 mm
UL 94 flammability rating	V-2	Operating temperature range, max.	90 °C
Operating temperature range, min.	-50 °C	Colour	yellow
Halogen	No	Length	24 mm
Basic material	PC-ABS, TPU	Printed characters	without
Size of labelling field	4.9 x 21.5 mm	Number per roll	600

**Conductor and cable markers**

Halogen	No	Conductor cross-section, max.	4 mm <sup>2</sup>
Conductor cross-section, min.	3.3 mm <sup>2</sup>	Conductor O.D., max.	4 mm
Conductor O.D., min.	2.5 mm	Conductor O.D.	2.5 - 4 mm
Cross-section for connected wire	3.3 - 4 mm <sup>2</sup>		

**Classifications**


ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		

### SFM 4/24 3.3-4.0 MM GE

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)


## Drawings

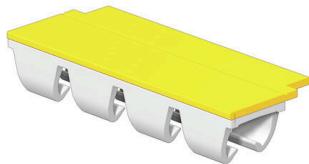

**SFM 4/24 3.3-4.0 MM GE**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergsstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

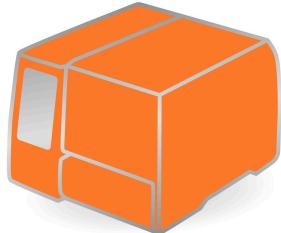**Accessories****THM MULTIMARK**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	MULTIMARK ROLLER SFM 4	Version
Order No.	<a href="#">2835010000</a>	
GTIN (EAN)	4064675427346	
Qty.	1 ST	

**Ink ribbons**

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

**General ordering data**

Type	RIBBON MM-TB 25/360 SW	Version
Order No.	<a href="#">2005090000</a>	Ink ribbon
GTIN (EAN)	4050118390216	
Qty.	1 ST	