


## AWPD 35 4X10

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

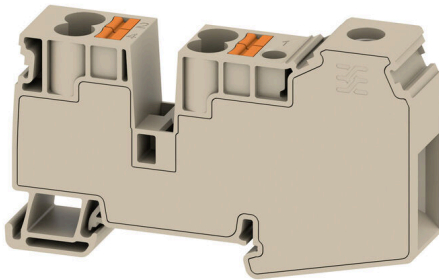

Our feed-in terminal blocks in combination with cross-connections offer the possibility of flexible potential distribution on terminal blocks with a different rated cross-section.

### General ordering data

|            |   |
|------------|---|
| Version    | Potential distributor terminal, Screw connection, dark beige, 35 mm <sup>2</sup> , 110 A, 1000 V, Number of connections: 5, Number of levels: 1 |
| Order No.  | <a href="#">2728630000</a>  |
| Type       | AWPD 35 4X10  |
| GTIN (EAN) | 4050118801118   |
| Qty.       | 20 items  |

## AWPD 35 4X10

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E60693

## Dimensions and weights

|            |          |                 |             |
|------------|----------|-----------------|-------------|
| Depth      | 51.6 mm  | Depth (inches)  | 2.0315 inch |
| Height     | 86.18 mm | Height (inches) | 3.3929 inch |
| Width      | 16.2 mm  | Width (inches)  | 0.6378 inch |
| Net weight | 40 g     |                 |             |

## Temperatures

|                                  |                |                                  |                |
|----------------------------------|----------------|----------------------------------|----------------|
| Storage temperature              | -25 °C...55 °C | Ambient temperature              | -60 °C...65 °C |
| Continuous operating temp., min. | -60 °C         | Continuous operating temp., max. | 110 °C         |

## Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

## Material data

|                                |        |                           |            |
|--------------------------------|--------|---------------------------|------------|
| Basic material                 | Wemid  | Colour                    | dark beige |
| Colour of operational elements | orange | UL 94 flammability rating | V-0        |

## System specifications

|                                     |  |                               |       |
|-------------------------------------|--|-------------------------------|-------|
| Version                             | Hybrid terminal, Potential distributor | End cover plate required      | No    |
| Number of potentials                | 1                                      | Number of levels              | 1     |
| Number of clamping points per level | 5                                      | Number of potentials per tier | 1     |
| Levels cross-connected internally   | No                                     | Mounting rail                 | TS 35 |
| N-function                          | No                                     | PE function                   | No    |
| PEN function                        | No                                     |                               |       |

## Additional technical data

|                          |        |                  |       |
|--------------------------|--------|------------------|-------|
| Open sides               | closed | Snap-on          | Yes   |
| Explosion-tested version | No     | Type of mounting | TS 35 |

## CSA rating data

|                      |       |                       |                 |
|----------------------|-------|-----------------------|-----------------|
| Current size C (CSA) | 600 V | Certificate No. (CSA) | 227442-80219640 |
|----------------------|-------|-----------------------|-----------------|

**AWPD 35 4X10**

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Technical data**

**Conductors for clamping (additional connection)**

|   |                     |   |                     |
|---|---------------------|---|---------------------|
| Connection direction additional connection  | top                 | Clamping range, further connection, max.  | 10 mm <sup>2</sup>  |
| Clamping range, further connection, min.  | 0.5 mm <sup>2</sup> | Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, max. | 10 mm <sup>2</sup>  |
| Conductor cross-section, flexible plus plastic collar DIN 46228/1, further connection, min. | 0.5 mm <sup>2</sup> | Conductor cross-section, flexible, further connection, min.                                 |                     |
| Number of connections, additional connection  | 4                   | Rated cross-section, further connection   | 6 mm <sup>2</sup>   |
| Blade size, additional connection   | 1.0 x 5.5 mm        | Cross-section for connected wire, multi-core, further connection, min.                      | 0.5 mm <sup>2</sup> |
| Cross-section for connected wire, multi-core, further connection, max.                      | 10 mm <sup>2</sup>  | Cross-section for connected wire, AWG, additional connection, min.                          | AWG 20              |
| Cross-section for connected wire, solid-core, further connection, min.                      | 0.5 mm <sup>2</sup> | Cross-section for connected wire, solid-core, further connection, max.                      | 0.5 mm <sup>2</sup> |
| Connection type, additional connection  | PUSH IN             | Cross-section for connected wire, flexible, further connection, max.                        | 10 mm <sup>2</sup>  |
| Cross-section for connected wire, AWG, additional connection, max.                          | AWG 6               | Stripping length, additional connection   | 18 mm               |

**Conductors for clamping (rated connection)**

|   |                     |   |                     |
|---|---------------------|---|---------------------|
| Gauge to IEC 60947-1  | B9                  | Wire connection cross section AWG, max.   | AWG 14              |
| Connection direction  | top                 | Tightening torque, max.   | 2.5 Nm              |
| Tightening torque, min.   | 2.5 Nm              | Stripping length  | 17 mm               |
| Type of connection 2  | PUSH IN             | Type of connection  | Screw connection    |
| Number of connections   | 5                   | Clamping range, max.  | 35 mm <sup>2</sup>  |
| Clamping range, min.  | 1.5 mm <sup>2</sup> | Clamping screw  | M 6                 |
| Blade size  | 1 x 5.5             | Wire connection cross section AWG, min.   | AWG 2               |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 35 mm <sup>2</sup>  | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 35 mm <sup>2</sup>  |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 1.5 mm <sup>2</sup> | Wire connection cross section, finely stranded, max.                                    | 35 mm <sup>2</sup>  |
| Wire connection cross section, finely stranded, min.                                    | 1.5 mm <sup>2</sup> | Connection cross-section, stranded, max.  | 35 mm <sup>2</sup>  |
| Twin wire-end ferrules, max.  | 6 mm <sup>2</sup>   | Twin wire-end ferrules, min.  | 1.5 mm <sup>2</sup> |
| Wire connection cross-section, solid core, max.   | 35 mm <sup>2</sup>  | Wire connection cross-section, solid core, min.   | 1.5 mm <sup>2</sup> |

**General**

|   |               |   |       |
|---|---------------|---|-------|
| Wire connection cross section AWG, max. | AWG 14        | Wire connection cross section AWG, min. | AWG 2 |
| Standards                               | IEC 60947-7-1 | Mounting rail                           | TS 35 |

**Rating data**

|                     |                    |  |         |
|---------------------|--------------------|--|---------|
| Rated cross-section | 35 mm <sup>2</sup> | Rated voltage                                | 1000 V  |
| Rated AC voltage    | 1000 V             | Rated DC voltage                             | 1000 V  |
| Nominal current     | 110 A              | Current at maximum wires                     | 110 A   |
| Standards           | IEC 60947-7-1      | Volume resistance according to IEC 60947-7-x | 0.26 mΩ |

## AWPD 35 4X10

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Technical data

|                                 |      |   |        |
|---------------------------------|------|---|--------|
| Rated impulse withstand voltage | 8 kV | Power loss in accordance with IEC 60947-7-x | 4.00 W |
| Surge voltage category          | III  | Pollution severity                          | 3      |


### UL rating data

|  |        |  |        |
|--|--------|--|--------|
| Conductor size Factory wiring max. (cURus) | 2 AWG  | Certificate No. (cURus)                    | E60693 |
| Conductor size Field wiring min. (cURus)   | 14 AWG | Conductor size Factory wiring min. (cURus) | 14 AWG |
| Conductor size Field wiring max. (cURus)   | 2 AWG  |  |        |

### Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000897    | ETIM 9.0    | EC000897    |
| ETIM 10.0   | EC000897    | ECLASS 14.0 | 27-25-01-19 |
| ECLASS 15.0 | 27-25-01-19 |             |             |

**Drawings**

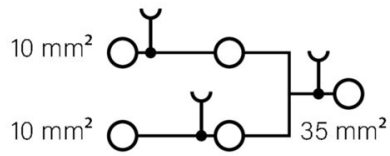

## AWPD 35 4X10

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

## Accessories

www.weidmueller.com

## WS 8/16

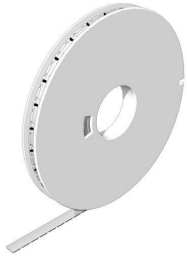

## WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.


## Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

## General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | WS-A 8/16 MM WS            | Version  |  |
| Order No.  | <a href="#">2619910000</a> | WS, Terminal marker, 8 x 16 mm, Weidmueller, white |  |
| GTIN (EAN) | 4050118626179              |  |  |
| Qty.       | 200 ST                     |  |  |

## End bracket

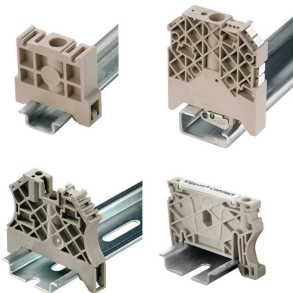

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

|            |                            |                       |  |
|------------|----------------------------|-----------------------|--|
| Type       | AEB 35 SCL/1 V0            | Version               |  |
| Order No.  | <a href="#">2661280000</a> | A-series, End bracket |  |
| GTIN (EAN) | 4050118702163              |                       |  |
| Qty.       | 20 ST                      |                       |  |
| Type       | AEB 35 SCL/1 V0 BK         | Version               |  |
| Order No.  | <a href="#">2661300000</a> | A-series, End bracket |  |
| GTIN (EAN) | 4050118702187              |                       |  |
| Qty.       | 20 ST                      |                       |  |
| Type       | AEB 35 SCL/1 V0 GY         | Version               |  |
| Order No.  | <a href="#">2661290000</a> | A-series, End bracket |  |
| GTIN (EAN) | 4050118702170              |                       |  |
| Qty.       | 20 ST                      |                       |  |

### Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

### General ordering data

|            |                            |   |
|------------|----------------------------|---|
| Type       | ZQV 1.5N/10                | Version   |
| Order No.  | <a href="#">1985580000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of poles: 10, Pitch in mm (P): 3.50, Insulated: Yes, Width: 33.5 mm |
| GTIN (EAN) | 4050118370416              |   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 1.5N/10 BL             | Version   |
| Order No.  | <a href="#">1985680000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 10, Pitch in mm (P): 3.50, Insulated: Yes, Width: 33.5 mm   |
| GTIN (EAN) | 4050118370539              |   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 1.5N/10 RD             | Version   |
| Order No.  | <a href="#">1985800000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 10, Pitch in mm (P): 3.50, Insulated: Yes, Width: 33.5 mm    |
| GTIN (EAN) | 4050118370393              |   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 1.5N/2                 | Version   |
| Order No.  | <a href="#">1985410000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of poles: 2, Pitch in mm (P): 3.50, Insulated: Yes, Width: 5.5 mm   |
| GTIN (EAN) | 4050118369861              |   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 1.5N/2 BL              | Version   |
| Order No.  | <a href="#">1985530000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 2, Pitch in mm (P): 3.50, Insulated: Yes, Width: 5.5 mm     |
| GTIN (EAN) | 4050118370423              |   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 1.5N/2 RD              | Version   |
| Order No.  | <a href="#">1985650000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 2, Pitch in mm (P): 3.50, Insulated: Yes, Width: 5.5 mm      |
| GTIN (EAN) | 4050118370324              |   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 1.5N/20 BL             | Version   |
| Order No.  | <a href="#">1985700000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 20, Pitch in mm (P): 3.50, Insulated: Yes, Width: 70 mm     |
| GTIN (EAN) | 4050118370331              |   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 1.5N/20                | Version   |
| Order No.  | <a href="#">1985600000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of poles: 20, Pitch in mm (P): 3.50, Insulated: Yes, Width: 70 mm   |
| GTIN (EAN) | 4050118370225              |   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 1.5N/20 RD             | Version   |
| Order No.  | <a href="#">1985810000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 20, Pitch in mm (P): 3.50, Insulated: Yes, Width: 70 mm      |
| GTIN (EAN) | 4050118370355              |   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 1.5N/3                 | Version   |
| Order No.  | <a href="#">1985480000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of poles: 3, Pitch in mm (P): 3.50, Insulated: Yes, Width: 9 mm     |
| GTIN (EAN) | 4050118370096              |   |
| Qty.       | 60 ST                      |   |

## AWPD 35 4X10

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | ZQV 1.5N/3 BL              | Version  |
| Order No.  | <a href="#">1985550000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 3, |
| GTIN (EAN) | 4050118370485              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 9 mm                     |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 1.5N/4                 | Version  |
| Order No.  | <a href="#">1985490000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118370201              | poles: 4, Pitch in mm (P): 3.50, Insulated: Yes, Width: 12.5 mm        |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 1.5N/4 BL              | Version  |
| Order No.  | <a href="#">1985570000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 4, |
| GTIN (EAN) | 4050118370317              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 12.5 mm                  |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 1.5N/4 RD              | Version  |
| Order No.  | <a href="#">1985690000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 4,  |
| GTIN (EAN) | 4050118370515              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 12.5 mm                  |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 1.5N/5                 | Version  |
| Order No.  | <a href="#">1985500000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118369991              | poles: 5, Pitch in mm (P): 3.50, Insulated: Yes, Width: 16 mm          |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/5 BL              | Version  |
| Order No.  | <a href="#">1985590000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 5, |
| GTIN (EAN) | 4050118370430              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 16 mm                    |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/5 RD              | Version  |
| Order No.  | <a href="#">1985710000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 5,  |
| GTIN (EAN) | 4050118370256              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 16 mm                    |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/50                | Version  |
| Order No.  | <a href="#">1985620000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118370300              | poles: 50, Pitch in mm (P): 3.50, Insulated: Yes, Width: 175 mm        |
| Qty.       | 5 ST                       |  |
| Type       | ZQV 1.5N/50 BL             | Version  |
| Order No.  | <a href="#">1985720000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles:    |
| GTIN (EAN) | 4050118370546              | 50, Pitch in mm (P): 3.50, Insulated: Yes, Width: 175 mm               |
| Qty.       | 5 ST                       |  |
| Type       | ZQV 1.5N/50 RD             | Version  |
| Order No.  | <a href="#">1985820000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles:     |
| GTIN (EAN) | 4050118370270              | 50, Pitch in mm (P): 3.50, Insulated: Yes, Width: 175 mm               |
| Qty.       | 5 ST                       |  |
| Type       | ZQV 1.5N/6                 | Version  |
| Order No.  | <a href="#">1985510000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118370188              | poles: 6, Pitch in mm (P): 3.50, Insulated: Yes, Width: 19.5 mm        |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/6 BL              | Version  |
| Order No.  | <a href="#">1985610000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 6, |
| GTIN (EAN) | 4050118370492              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 19.5 mm                  |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/6 RD              | Version  |
| Order No.  | <a href="#">1985730000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 6,  |
| GTIN (EAN) | 4050118370454              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 19.5 mm                  |
| Qty.       | 20 ST                      |  |

## AWPD 35 4X10

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | ZQV 1.5N/7                 | Version  |
| Order No.  | <a href="#">1985520000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118370195              | poles: 7, Pitch in mm (P): 3.50, Insulated: Yes, Width: 23 mm          |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/7 BL              | Version  |
| Order No.  | <a href="#">1985630000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 7, |
| GTIN (EAN) | 4050118370522              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 23 mm                    |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/7 RD              | Version  |
| Order No.  | <a href="#">1985750000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 7,  |
| GTIN (EAN) | 4050118370249              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 23 mm                    |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/8                 | Version  |
| Order No.  | <a href="#">1985540000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118370218              | poles: 8, Pitch in mm (P): 3.50, Insulated: Yes, Width: 26.5 mm        |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/8 BL              | Version  |
| Order No.  | <a href="#">1985640000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 8, |
| GTIN (EAN) | 4050118370461              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 26.5 mm                  |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/8 RD              | Version  |
| Order No.  | <a href="#">1985770000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 8,  |
| GTIN (EAN) | 4050118370508              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 26.5 mm                  |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/9                 | Version  |
| Order No.  | <a href="#">1985560000</a> | Cross-connector (terminal), Plugged, orange, 17.5 A, Number of         |
| GTIN (EAN) | 4050118370409              | poles: 9, Pitch in mm (P): 3.50, Insulated: Yes, Width: 30 mm          |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/9 BL              | Version  |
| Order No.  | <a href="#">1985660000</a> | Cross-connector (terminal), Plugged, blue, 17.5 A, Number of poles: 9, |
| GTIN (EAN) | 4050118370478              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 30 mm                    |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 1.5N/9 RD              | Version  |
| Order No.  | <a href="#">1985790000</a> | Cross-connector (terminal), Plugged, red, 17.5 A, Number of poles: 9,  |
| GTIN (EAN) | 4050118370386              | Pitch in mm (P): 3.50, Insulated: Yes, Width: 30 mm                    |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 2.5N/10                | Version  |
| Order No.  | <a href="#">1527690000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:    |
| GTIN (EAN) | 4050118447989              | 10, Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm              |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 2.5N/10 BL             | Version  |
| Order No.  | <a href="#">1527880000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 10,  |
| GTIN (EAN) | 4050118448573              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm                  |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 2.5N/10 RD             | Version  |
| Order No.  | <a href="#">2108910000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 10,   |
| GTIN (EAN) | 4050118486018              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 48.7 mm                  |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 2.5N/2                 | Version  |
| Order No.  | <a href="#">1527540000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:    |
| GTIN (EAN) | 4050118448467              | 2, Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                |
| Qty.       | 60 ST                      |  |

## AWPD 35 4X10

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

|            |                            |   |
|------------|----------------------------|---|
| Type       | ZQV 2.5N/2 BL              | Version   |
| Order No.  | <a href="#">1527740000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 2,    |
| GTIN (EAN) | 4050118448658              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                    |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/2 RD              | Version   |
| Order No.  | <a href="#">2108470000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 2,     |
| GTIN (EAN) | 4050118448542              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 7.9 mm                    |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/20                | Version   |
| Order No.  | <a href="#">1527720000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles: 20, |
| GTIN (EAN) | 4050118447972              | 20, Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/20 BL             | Version   |
| Order No.  | <a href="#">1527890000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 20,   |
| GTIN (EAN) | 4050118448566              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                    |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/20 RD             | Version   |
| Order No.  | <a href="#">2108920000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 20,    |
| GTIN (EAN) | 4050118448599              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 102 mm                    |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/3                 | Version   |
| Order No.  | <a href="#">1527570000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles: 3,  |
| GTIN (EAN) | 4050118448450              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                     |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/3 BL              | Version   |
| Order No.  | <a href="#">1527770000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 3,    |
| GTIN (EAN) | 4050118448641              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                     |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/3 RD              | Version   |
| Order No.  | <a href="#">2108690000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 3,     |
| GTIN (EAN) | 4050118448535              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 13 mm                     |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/4                 | Version   |
| Order No.  | <a href="#">1527590000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles: 4,  |
| GTIN (EAN) | 4050118448443              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/4 BL              | Version   |
| Order No.  | <a href="#">1527780000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 4,    |
| GTIN (EAN) | 4050118448634              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/4 RD              | Version   |
| Order No.  | <a href="#">2108700000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 4,     |
| GTIN (EAN) | 4050118448528              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 18.1 mm                   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 2.5N/5                 | Version   |
| Order No.  | <a href="#">1527620000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles: 5,  |
| GTIN (EAN) | 4050118448436              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                   |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/5 BL              | Version   |
| Order No.  | <a href="#">1527790000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 5,    |
| GTIN (EAN) | 4050118448627              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                   |
| Qty.       | 20 ST                      |   |

## Accessories

|            |                            |   |
|------------|----------------------------|---|
| Type       | ZQV 2.5N/5 RD              | Version   |
| Order No.  | <a href="#">2108710000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 5,   |
| GTIN (EAN) | 4050118448511              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 23.2 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/50                | Version   |
| Order No.  | <a href="#">1527730000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118411362              | 50, Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm              |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 2.5N/50 BL             | Version   |
| Order No.  | <a href="#">1527920000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 50, |
| GTIN (EAN) | 4050118448559              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm                  |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 2.5N/50 RD             | Version   |
| Order No.  | <a href="#">2109000000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 50,  |
| GTIN (EAN) | 4050118486001              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 255 mm                  |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 2.5N/6                 | Version   |
| Order No.  | <a href="#">1527630000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448429              | 6, Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm              |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/6 BL              | Version   |
| Order No.  | <a href="#">1527820000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 6,  |
| GTIN (EAN) | 4050118448610              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/6 RD              | Version   |
| Order No.  | <a href="#">2108720000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 6,   |
| GTIN (EAN) | 4050118448504              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 28.3 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/7                 | Version   |
| Order No.  | <a href="#">1527640000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448412              | 7, Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm              |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/7 BL              | Version   |
| Order No.  | <a href="#">1527830000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 7,  |
| GTIN (EAN) | 4050118448603              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/7 RD              | Version   |
| Order No.  | <a href="#">2108810000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 7,   |
| GTIN (EAN) | 4050118448498              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 33.4 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/8                 | Version   |
| Order No.  | <a href="#">1527670000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118448405              | 8, Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm              |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/8 BL              | Version   |
| Order No.  | <a href="#">1527840000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 6,  |
| GTIN (EAN) | 4050118448597              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/8 RD              | Version   |
| Order No.  | <a href="#">2108870000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 8,   |
| GTIN (EAN) | 4050118448481              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 38.5 mm                 |
| Qty.       | 20 ST                      |   |

## AWPD 35 4X10

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |   |
|------------|----------------------------|---|
| Type       | ZQV 2.5N/9                 | Version   |
| Order No.  | <a href="#">1527680000</a> | Cross-connector (terminal), Plugged, orange, 24 A, Number of poles:   |
| GTIN (EAN) | 4050118447996              | 9, Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm              |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/9 BL              | Version   |
| Order No.  | <a href="#">1527870000</a> | Cross-connector (terminal), Plugged, blue, 24 A, Number of poles: 9,  |
| GTIN (EAN) | 4050118448580              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 2.5N/9 RD              | Version   |
| Order No.  | <a href="#">2108900000</a> | Cross-connector (terminal), Plugged, red, 24 A, Number of poles: 9,   |
| GTIN (EAN) | 4050118448474              | Pitch in mm (P): 5.10, Insulated: Yes, Width: 43.6 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 4N/10                  | Version   |
| Order No.  | <a href="#">1528090000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332896              | 10, Pitch in mm (P): 6.10, Insulated: Yes, Width: 58.7 mm             |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 4N/10 BL               | Version   |
| Order No.  | <a href="#">1528230000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 10, |
| GTIN (EAN) | 4050118333138              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 58.7 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 4N/10 RD               | Version   |
| Order No.  | <a href="#">2460740000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 10,  |
| GTIN (EAN) | 4050118476163              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 58.7 mm                 |
| Qty.       | 20 ST                      |   |
| Type       | ZQV 4N/2                   | Version   |
| Order No.  | <a href="#">1527930000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332766              | 2, Pitch in mm (P): 6.10, Insulated: Yes, Width: 9.9 mm               |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/2 BL                | Version   |
| Order No.  | <a href="#">1528040000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 2,  |
| GTIN (EAN) | 4050118332773              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 9.9 mm                  |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/2 RD                | Version   |
| Order No.  | <a href="#">2460450000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 2,   |
| GTIN (EAN) | 4050118476149              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 9.9 mm                  |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/3                   | Version   |
| Order No.  | <a href="#">1527940000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332865              | 3, Pitch in mm (P): 6.10, Insulated: Yes, Width: 16 mm                |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/3 BL                | Version   |
| Order No.  | <a href="#">1528080000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 3,  |
| GTIN (EAN) | 4050118333008              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 16 mm                   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/3 RD                | Version   |
| Order No.  | <a href="#">2460810000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 3,   |
| GTIN (EAN) | 4050118476231              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 16 mm                   |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/30 BL               | Version   |
| Order No.  | <a href="#">2561610000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 30, |
| GTIN (EAN) | 4050118569971              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 181.7 mm                |
| Qty.       | 5 ST                       |   |

## AWPD 35 4X10

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |   |
|------------|----------------------------|---|
| Type       | ZQV 4N/30                  | Version   |
| Order No.  | <a href="#">2561580000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118570113              | 30, Pitch in mm (P): 6.10, Insulated: Yes, Width: 181.7 mm            |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 4N/30 RD               | Version   |
| Order No.  | <a href="#">2561600000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 30,  |
| GTIN (EAN) | 4050118569964              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 181.7 mm                |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 4N/32                  | Version   |
| Order No.  | <a href="#">2561670000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118570175              | 32, Pitch in mm (P): 6.10, Insulated: Yes, Width: 193.9 mm            |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 4N/4                   | Version   |
| Order No.  | <a href="#">1527970000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332889              | 4, Pitch in mm (P): 6.10, Insulated: Yes, Width: 22.1 mm              |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/4 BL                | Version   |
| Order No.  | <a href="#">1528120000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 4,  |
| GTIN (EAN) | 4050118332872              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 22.1 mm                 |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/4 RD                | Version   |
| Order No.  | <a href="#">2460800000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 4,   |
| GTIN (EAN) | 4050118476224              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 22.1 mm                 |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/5                   | Version   |
| Order No.  | <a href="#">1527980000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332759              | 5, Pitch in mm (P): 6.10, Insulated: Yes, Width: 28.2 mm              |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/5 BL                | Version   |
| Order No.  | <a href="#">1528140000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 5,  |
| GTIN (EAN) | 4050118333015              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 28.2 mm                 |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/5 RD                | Version   |
| Order No.  | <a href="#">2460790000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 5,   |
| GTIN (EAN) | 4050118476217              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 28.2 mm                 |
| Qty.       | 60 ST                      |   |
| Type       | ZQV 4N/50                  | Version   |
| Order No.  | <a href="#">1528130000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332902              | 50, Pitch in mm (P): 6.10, Insulated: Yes, Width: 303.7 mm            |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 4N/50 BL               | Version   |
| Order No.  | <a href="#">1528240000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 50, |
| GTIN (EAN) | 4050118333121              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 303.7 mm                |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 4N/50 RD               | Version   |
| Order No.  | <a href="#">2460730000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 50,  |
| GTIN (EAN) | 4050118476156              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 303.7 mm                |
| Qty.       | 5 ST                       |   |
| Type       | ZQV 4N/6                   | Version   |
| Order No.  | <a href="#">1527990000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:   |
| GTIN (EAN) | 4050118332919              | 6, Pitch in mm (P): 6.10, Insulated: Yes, Width: 34.3 mm              |
| Qty.       | 20 ST                      |   |

## AWPD 35 4X10

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | ZQV 4N/6 BL                | Version  |
| Order No.  | <a href="#">1528170000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 6, |
| GTIN (EAN) | 4050118332926              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 34.3 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/6 RD                | Version  |
| Order No.  | <a href="#">2460780000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 6,  |
| GTIN (EAN) | 4050118476200              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 34.3 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/7                   | Version  |
| Order No.  | <a href="#">1528020000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:  |
| GTIN (EAN) | 4050118332780              | 7, Pitch in mm (P): 6.10, Insulated: Yes, Width: 40.4 mm             |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/7 BL                | Version  |
| Order No.  | <a href="#">1528180000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 7, |
| GTIN (EAN) | 4050118333114              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 40.4 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/7 RD                | Version  |
| Order No.  | <a href="#">2460770000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 7,  |
| GTIN (EAN) | 4050118476194              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 40.4 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/8                   | Version  |
| Order No.  | <a href="#">1528030000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:  |
| GTIN (EAN) | 4050118332841              | 8, Pitch in mm (P): 6.10, Insulated: Yes, Width: 46.5 mm             |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/8 BL                | Version  |
| Order No.  | <a href="#">1528190000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 8, |
| GTIN (EAN) | 4050118332858              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 46.5 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/8 RD                | Version  |
| Order No.  | <a href="#">2460760000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 8,  |
| GTIN (EAN) | 4050118476187              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 46.5 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/9                   | Version  |
| Order No.  | <a href="#">1528070000</a> | Cross-connector (terminal), Plugged, orange, 32 A, Number of poles:  |
| GTIN (EAN) | 4050118332797              | 9, Pitch in mm (P): 6.10, Insulated: Yes, Width: 52.6 mm             |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/9 BL                | Version  |
| Order No.  | <a href="#">1528220000</a> | Cross-connector (terminal), Plugged, blue, 32 A, Number of poles: 9, |
| GTIN (EAN) | 4050118333107              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 52.6 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 4N/9 RD                | Version  |
| Order No.  | <a href="#">2460750000</a> | Cross-connector (terminal), Plugged, red, 32 A, Number of poles: 9,  |
| GTIN (EAN) | 4050118476170              | Pitch in mm (P): 6.10, Insulated: Yes, Width: 52.6 mm                |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 6N/10                  | Version  |
| Order No.  | <a href="#">2733970000</a> | Cross-connector (terminal), Plugged, orange, 41 A, Number of poles:  |
| GTIN (EAN) | 4064675066811              | 10, Pitch in mm (P): 8.00, Insulated: Yes, Width: 78.5 mm            |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 6N/2                   | Version  |
| Order No.  | <a href="#">1985740000</a> | Cross-connector (terminal), Plugged, orange, 41 A, Number of poles:  |
| GTIN (EAN) | 4050118370362              | 2, Pitch in mm (P): 8.00, Insulated: Yes, Width: 13.7 mm             |
| Qty.       | 60 ST                      |  |

## AWPD 35 4X10

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

|            |                            |  |
|------------|----------------------------|--|
| Type       | ZQV 6N/2 BL                | Version  |
| Order No.  | <a href="#">1985830000</a> | Cross-connector (terminal), Plugged, blue, 41 A, Number of poles: 2, |
| GTIN (EAN) | 4050118370232              | Pitch in mm (P): 8.00, Insulated: Yes, Width: 13.7 mm                |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 6N/3                   | Version  |
| Order No.  | <a href="#">1985760000</a> | Cross-connector (terminal), Plugged, orange, 41 A, Number of poles:  |
| GTIN (EAN) | 4050118370263              | 3, Pitch in mm (P): 8.00, Insulated: Yes, Width: 21.8 mm             |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 6N/3 BL                | Version  |
| Order No.  | <a href="#">1985840000</a> | Cross-connector (terminal), Plugged, blue, 41 A, Number of poles: 3, |
| GTIN (EAN) | 4050118370379              | Pitch in mm (P): 8.00, Insulated: Yes, Width: 21.8 mm                |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 6N/4                   | Version  |
| Order No.  | <a href="#">1985780000</a> | Cross-connector (terminal), Plugged, orange, 41 A, Number of poles:  |
| GTIN (EAN) | 4050118370287              | 4, Pitch in mm (P): 8.00, Insulated: Yes, Width: 29.9 mm             |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 6N/4 BL                | Version  |
| Order No.  | <a href="#">1985850000</a> | Cross-connector (terminal), Plugged, blue, 41 A, Number of poles: 4, |
| GTIN (EAN) | 4050118370447              | Pitch in mm (P): 8.00, Insulated: Yes, Width: 29.9 mm                |
| Qty.       | 60 ST                      |  |
| Type       | ZQV 6N/6                   | Version  |
| Order No.  | <a href="#">2733950000</a> | Cross-connector (terminal), Plugged, orange, 41 A, Number of poles:  |
| GTIN (EAN) | 4064675066699              | 6, Pitch in mm (P): 8.00, Insulated: Yes, Width: 46.1 mm             |
| Qty.       | 20 ST                      |  |
| Type       | ZQV 6N/7                   | Version  |
| Order No.  | <a href="#">2733960000</a> | Cross-connector (terminal), Plugged, orange, 41 A, Number of poles:  |
| GTIN (EAN) | 4064675066804              | 7, Pitch in mm (P): 8.00, Insulated: Yes, Width: 54.2 mm             |
| Qty.       | 20 ST                      |  |

## Testadapter and testsockets



Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

## General ordering data

|            |                            |  |
|------------|----------------------------|--|
| Type       | FZS 2/4 RT/80 SAKT4        | Version  |
| Order No.  | <a href="#">1276300000</a> | Plug (terminal), Plug-in connection, 2 mm <sup>2</sup> , Number of connections: 2, |
| GTIN (EAN) | 4008190026080              | Number of poles: 1, Width: 9 mm  |
| Qty.       | 20 ST                      |  |