


**VPU LOCKING CLIP L**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

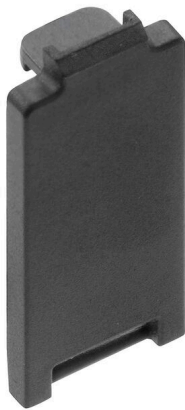

Extensive accessories round off the product range

**General ordering data**

Order No.	2735070000
Type	<a href="#">VPU LOCKING CLIP L</a>
GTIN (EAN)	4050118816402
Qty.	10 items

**VPU LOCKING CLIP L**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	7.5 mm	Depth (inches)	0.2953 inch
Height	13 mm	Height (inches)	0.5118 inch
Width	17 mm	Width (inches)	0.6693 inch
Net weight	0.65 g		

**Temperatures**

Storage temperature		Ambient temperature	...70 °C
Operating temperature	-40 °C...70 °C		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**General data**

Version	Latches	Design	miscellaneous
UL 94 flammability rating	V-0	Colour	black
Protection degree	IP20		

**Rated data IEC / EN**

Frequency range, max.	60 Hz	Frequency range, min.	50 Hz
Integrated back-up fuse	No		

**General data**

Protection degree	IP20	Colour	black
-------------------	------	--------	-------

**Classifications**

ETIM 8.0	EC002496	ETIM 9.0	EC002496
ETIM 10.0	EC002496	ECLASS 14.0	27-17-90-90
ECLASS 15.0	27-17-90-90		