


VPU LOCKING CLIP L

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

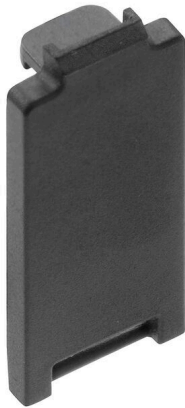

Extensive accessories round off the product range

General ordering data

Order No.	2735070000
Type	VPU LOCKING CLIP L
GTIN (EAN)	4050118816402
Qty.	10 items

VPU LOCKING CLIP L

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	7.5 mm	Depth (inches)	0.2953 inch
Height	13 mm	Height (inches)	0.5118 inch
Width	17 mm	Width (inches)	0.6693 inch
Net weight	0.65 g		

Temperatures

Storage temperature		Ambient temperature	...70 °C
Operating temperature	-40 °C...70 °C		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Version	Latches	Design	miscellaneous
UL 94 flammability rating	V-0	Colour	black
Protection degree	IP20		

Rated data IEC / EN

Frequency range, max.	60 Hz	Frequency range, min.	50 Hz
Integrated back-up fuse	No		

General data

Protection degree	IP20	Colour	black
-------------------	------	--------	-------

Classifications

ETIM 8.0	EC002496	ETIM 9.0	EC002496
ETIM 10.0	EC002496	ECLASS 14.0	27-17-90-90
ECLASS 15.0	27-17-90-90		