

CA 100 DUO

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



- For automatic stripping and crimping
- Time-saving and efficient processing
- Easily adjustable to the respective cross-section range
- Stripping and crimping in one work step
- The processing of sleeves or contacts from other manufacturers can cause machine failures and defects!

General ordering data

Version	Automatic stripper and crimper, 6mm ² , 10mm ²
Order No.	2740900000
Type	CA 100 DUO
GTIN (EAN)	4050118835700
Qty.	1 items

CA 100 DUO

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Depth	550 mm	Depth (inches)	21.6535 inch
Height	440 mm	Height (inches)	17.3228 inch
Width	415 mm	Width (inches)	16.3386 inch
Net weight	40000 g		

Environmental Product Compliance

RoHS Compliance Status Compliant
 REACH SVHC Lead 7439-92-1

PW65 maintenance - automatic stripping/crimping

Stripping range	6 - 10 mm ² (4 mm ² opt.) / AWG 10-8 (AWG 12 opt.)	Drive	Electropneumatic
Pulse time	approx. 3 s	Crimping	Trapezoidal
Wire end ferrules cross-section, max.	10 mm ²	Wire end ferrules cross-section, min.	6 mm ²
Crimping range, max.	10 mm ²	Crimping range, min.	6 mm ²
Crimping length	8 - 18 mm	Consumables	with plastic collar
Compressed-air connection	5 - 5.5 bar	Electrical connection	100-240 V / 50/60 Hz / 100 VA

Classifications

ETIM 8.0	EC002778	ETIM 9.0	EC002778
ETIM 10.0	EC002778	ECLASS 14.0	17-13-01-01
ECLASS 15.0	17-13-01-01		

CA 100 DUO

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

packed loose in polythene bag




- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

Type	H4,0/18D GR	Version
Order No.	9019190000	Wire-end ferrule, Standard, 12 mm, 10 mm, grey
GTIN (EAN)	4008190141349	
Qty.	500 ST	
Type	H4,0/20D GR	Version
Order No.	9019200000	Wire-end ferrule, Standard, 14 mm, 12 mm, grey
GTIN (EAN)	4008190126575	
Qty.	500 ST	
Type	H4,0/26D GR	Version
Order No.	9019210000	Wire-end ferrule, Standard, 20 mm, 18 mm, grey
GTIN (EAN)	4008190002336	
Qty.	100 ST	

Conductor nom. cross-section 6.0mm²

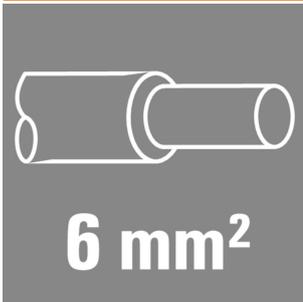

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H6,0/20 SW	Version
Order No.	0533500000	Wire-end ferrule, Standard, 14 mm, 12 mm, black
GTIN (EAN)	4008190183905	
Qty.	100 ST	
Type	H6,0/26 SW	Version
Order No.	0565700000	Wire-end ferrule, Standard, 20 mm, 18 mm, black
GTIN (EAN)	4008190026837	
Qty.	100 ST	


CA 100 DUO

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Conductor nom. cross-section 10mm²

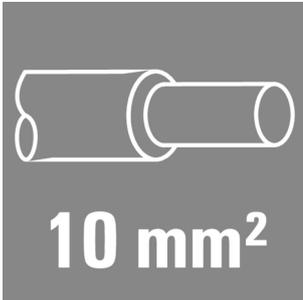


- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H10,0/22 EB	Version
Order No.	0534200000	Wire-end ferrule, Standard, 15 mm, 12 mm, Ivory
GTIN (EAN)	4008190033460	
Qty.	100 ST	

Type	H10,0/28 EB	Version
Order No.	0565800000	Wire-end ferrule, Standard, 21 mm, 18 mm, Ivory
GTIN (EAN)	4008190138646	
Qty.	100 ST	

Conductor nom. cross-section 6.0mm²

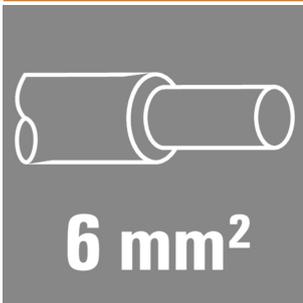

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H6,0/20D GE	Version
Order No.	9019220000	Wire-end ferrule, Standard, 14 mm, 12 mm, yellow
GTIN (EAN)	4008190151607	
Qty.	100 ST	

Type	H6,0/26D GE	Version
Order No.	9019230000	Wire-end ferrule, Standard, 20 mm, 18 mm, yellow
GTIN (EAN)	4008190072117	
Qty.	100 ST	


CA 100 DUO

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Conductor nom. cross-section 10mm²

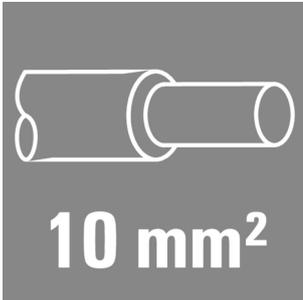

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H10,0/22D R	Version	
Order No.	9019240000	Wire-end ferrule, Standard, 15 mm, 12 mm, red	
GTIN (EAN)	4008190075385		
Qty.	100 ST		

Type	H10,0/28D R	Version	
Order No.	9019250000	Wire-end ferrule, Standard, 21 mm, 18 mm, red	
GTIN (EAN)	4008190041410		
Qty.	100 ST		

packed loose in polythene bag



- supplied loose in polybag
- DIN colour code
- other colour code

General ordering data

Type	H4,0/18T OR	Version	
Order No.	9021100000	Wire-end ferrule, Standard, 12 mm, 10 mm, orange	
GTIN (EAN)	4008190061708		
Qty.	500 ST		

Type	H4,0/20T OR	Version	
Order No.	9021110000	Wire-end ferrule, Standard, 14 mm, 12 mm, orange	
GTIN (EAN)	4008190035754		
Qty.	500 ST		

Type	H4,0/26T OR	Version	
Order No.	9021120000	Wire-end ferrule, Standard, 20 mm, 18 mm, orange	
GTIN (EAN)	4008190092825		
Qty.	100 ST		


CA 100 DUO

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Conductor nom. cross-section 6.0mm²

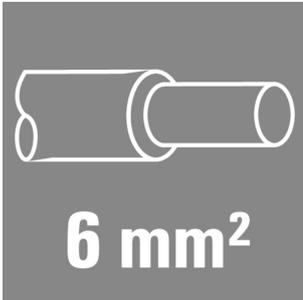


- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H6,0/20T GN	Version	
Order No.	9021130000	Wire-end ferrule, Standard, 14 mm, 12 mm, green	
GTIN (EAN)	4008190111731		
Qty.	100 ST		

Type	H6,0/26T GN	Version	
Order No.	9021140000	Wire-end ferrule, Standard, 20 mm, 18 mm, green	
GTIN (EAN)	4008190022501		
Qty.	100 ST		

Conductor nom. cross-section 10mm²

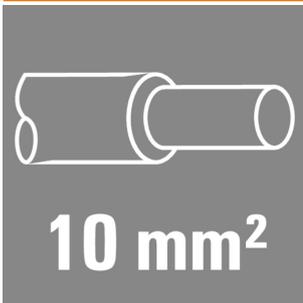

- supplied loose in polybag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Type	H10,0/22T BR	Version	
Order No.	9021150000	Wire-end ferrule, Standard, 15 mm, 12 mm, brown	
GTIN (EAN)	4008190086886		
Qty.	100 ST		

Type	H10,0/28T BR	Version	
Order No.	9021160000	Wire-end ferrule, Standard, 21 mm, 18 mm, brown	
GTIN (EAN)	4008190041915		
Qty.	100 ST		

CA 100 DUO

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Accessories / replacement parts



- For automatic stripping and crimping
- Time-saving and efficient processing
- Easily adjustable to the respective cross-section range
- Stripping and crimping in one work step
- The processing of sleeves or contacts from other manufacturers can cause machine failures and defects!

General ordering data

Type	URS CA 100 DUO 4-6MM ²	Version
Order No.	2769020000	
GTIN (EAN)	4064675026303	
Qty.	1 ST	
Type	URS CA 100 DUO 4-10MM ²	Version
Order No.	2769030000	
GTIN (EAN)	4064675026310	
Qty.	1 ST	
Type	AIMESA VRM 3,49	Version
Order No.	2007380000	Accessories, Set of cutters
GTIN (EAN)	4050118392753	
Qty.	1 ST	

Automatic machines



- For automatic stripping and crimping
- Time-saving and efficient processing
- Easily adjustable to the respective cross-section range
- Stripping and crimping in one work step
- The processing of sleeves or contacts from other manufacturers can cause machine failures and defects!

General ordering data

Type	CA 100 DUO S	Version
Order No.	2912430000	Automatic machines, Automatic stripper and crimper
GTIN (EAN)	4099986536005	
Qty.	1 ST	