

**HDC MBUS HD 4 M**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Flexible**

The four module sizes make for individual plug solutions that save a huge amount of space. The smaller pitch translates into an optimised design too.

**General ordering data**

Version	Data use, 50 V, 10 A, Number of poles: 4, Crimp connection, Male, Required plug-in slots: 0
Order No.	<a href="#">2748590000</a>
Type	HDC MBUS HD 4 M
GTIN (EAN)	4050118890723
Qty.	1 items

## HDC MBUS HD 4 M

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

Approvals



ROHS Conform

### Dimensions and weights

Depth	46 mm	Depth (inches)	1.811 inch
Height	15.5 mm	Height (inches)	0.6102 inch
Width	18 mm	Width (inches)	0.7087 inch
Net weight	31 g		

### Temperatures

Limit temperature -40 °C ... 125 °C

### Environmental Product Compliance

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

### General data

Number of poles	4	UL 94 flammability rating	V-0
Plugging cycles	≥ 500	Type	Male
Surge voltage category	III	Pollution severity	3
Basic material	Polycarbonate	Rated voltage (DIN EN 61984)	50 V
Rated impulse voltage (DIN EN 61984)	0.8 kV	Rated current (DIN EN 61984)	10 A
Required plug-in slots	0		

### Version

Type of connection Crimp connection Conductor cross-section, max. 2.5 mm<sup>2</sup>  
 Conductor cross-section, min. 0.14 mm<sup>2</sup>

### Classifications

ETIM 8.0	EC000438	ETIM 9.0	EC000438
ETIM 10.0	EC000438	ECLASS 14.0	27-44-02-18
ECLASS 15.0	27-44-02-18		


HDC MBUS HD 4 M

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

Drawings

Drawing

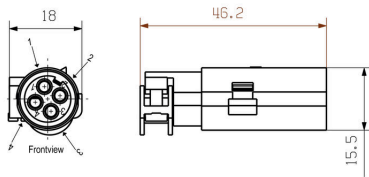

Drawing

