

## BCC 4/3


**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)

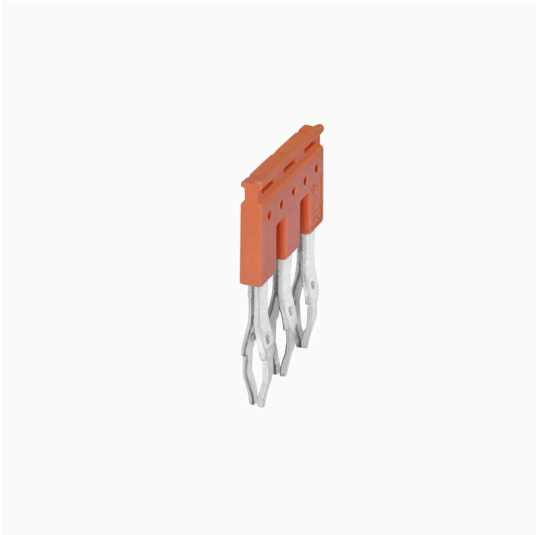

### General ordering data

Version	Cross-connector (terminal), Plugged, orange, 32 A, Number of poles: 3, Pitch in mm (P): 6.00, Insulated: Yes, Width: 15.4 mm
Order No.	<a href="#">2791230000</a>
Type	BCC 4/3
GTIN (EAN)	4064675070429
Qty.	50 items
Local product	Only available in certain countries

**BCC 4/3**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**General ordering data**

Local product Only available in certain countries

**Dimensions and weights**

Depth	2.5 mm	Depth (inches)	0.0984 inch
Height	23 mm	Height (inches)	0.9055 inch
Width	15.4 mm	Width (inches)	0.6063 inch
Net weight	1.93 g		

**Temperatures**

Storage temperature -25 °C...55 °C      Operating temperature -50 °C...120 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**Material data**

Basic material PA 66/6      Colour orange  
 UL 94 flammability rating V-0

**Additional technical data**

Type of fixing Plugged      Explosion-tested version Yes

**Dimensions**

Pitch in mm (P) 6.00 mm

**General**

Number of poles 3

**Rating data**

Nominal current 32 A

**Classifications**

ETIM 8.0	EC000489	ETIM 9.0	EC000489
ETIM 10.0	EC000489	ECLASS 14.0	27-25-03-03
ECLASS 15.0	27-25-03-03		