


THM PV EL 90 GE 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

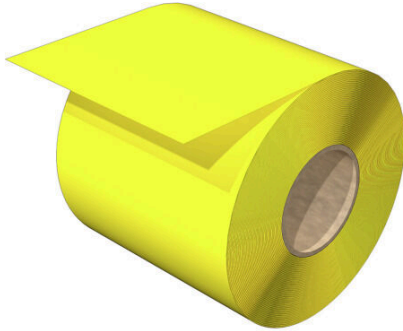

UV-radiation causes high stress and aging of plastic in the outdoor application.

Our new THM PV labels resist these influences and are extremely durable in outdoor use.

Compact designed packaging are our TABPACK-PV. These are pre-printed warning labels, which should be a part of the basic equipment of a professional photovoltaic builder.

Your advantages at a glance:

- Weathering resistance tested according to ISO DIN EN ISO 4892-2:2013 table 3, procedure A cycle 1 at 5000 hours
- Individually labeled with the M-Print® PRO
- Easy and fast printing with the THM MultiMark

General ordering data

| | |
|------------|---|
| Version | Device markers, Device markers, 90 x , yellow |
| Order No. | 2817440000 |
| Type | THM PV EL 90 GE 30M |
| GTIN (EAN) | 4064675322757 |
| Qty. | 1 items |

THM PV EL 90 GE 30M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Depth | 0.1 mm | Depth (inches) | 0.0039 inch |
| Height | 90 mm | Height (inches) | 3.5433 inch |
| Length | 30000 mm | Length (inches) | 1181.1 inch |
| Net weight | 290 g | | |

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

| | | | |
|-----------------------------------|-----------------------|-----------------------------------|--|
| Adhesive | Polyacrylate adhesive | Version | Self-adhesive |
| UL 94 flammability rating | V-0 | Operating temperature range, max. | 110 °C |
| Operating temperature range, min. | -50 °C | Colour | yellow |
| Halogen | Yes | Length | 30000 mm |
| Basic material | Vinyl film | Printed characters | without |
| Approval acc. to UL 969 | Yes | compatible printer | THM MULTIMARK , THM MULTIMARK PLUS |

Conductor and cable markers

Halogen Yes


Device markers

Halogen Yes

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ETIM 10.0 | EC001288 | ECLASS 14.0 | 27-28-11-04 |
| ECLASS 15.0 | 27-28-11-04 | | |

Drawings

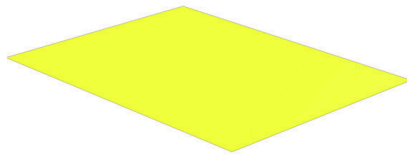

THM PV EL 90 GE 30M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON MM 110/360 SW | Version | |
| Order No. | 2005070000 | Ink ribbon | |
| GTIN (EAN) | 4050118390049 | | |
| Qty. | 1 ST | | |

THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | MULTIMARK ROLLER 115 | Version | |
| Order No. | 1357420000 | | |
| GTIN (EAN) | 4050118160314 | | |
| Qty. | 1 ST | | |

THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | MULTIMARK PLUS ROLLER 1... | Version | |
| Order No. | 2672590000 | | |
| GTIN (EAN) | 4050118708097 | | |
| Qty. | 1 ST | | |