


CH-SMC-00.33-Y2C180/90

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

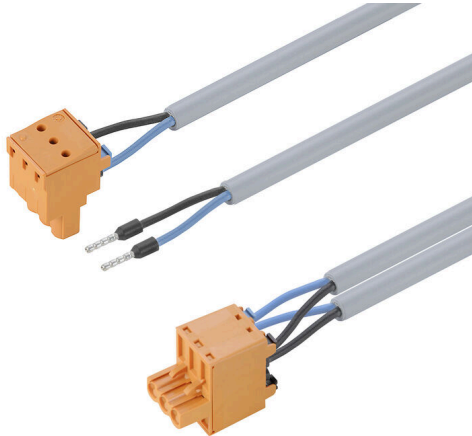

Base counter, gateway, control box and overvoltage protection device are connected with pre-assembled cable sets as point-to-point or Y-assembly. Weidmüller offers the right connection solutions for this, conforming to FNN and DIN-VDE 0603 standards. Pre-assembled power cables with 6kV overvoltage protection round up the portfolio.

General ordering data

Version	, IP20, 600 V
Order No.	2817670033
Type	CH-SMC-00.33-Y2C180/90
GTIN (EAN)	4064675323099
Qty.	10 items

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 10.1 g

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General Technical Data

Number of poles	2	Nominal voltage	600 V
Nominal current	18.5 A	Protection degree	IP20

Technical Specifications Connector

Connector	Number of poles	2
	Number of poles	2
	Number of poles	2

Technical specifications for cable

Cable length	0.33 m	Sheathing colour	grey
Core cross-section	1.5 mm ²	Number of wires	2
Shielded	No	Halogen	No
Insulation	PP	Temperature range, moving, max.	90 °C
Temperature range, moving, min.	-25 °C	Temperature range, stationary, max.	90 °C
Temperature range, stationary, min.	-40 °C		

Classifications

ETIM 8.0	EC001576	ETIM 9.0	EC001576
ETIM 10.0	EC001576	ECLASS 14.0	27-06-04-02
ECLASS 15.0	27-06-04-02		