


## IE-TO-RJ45-C-ZP-C5

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

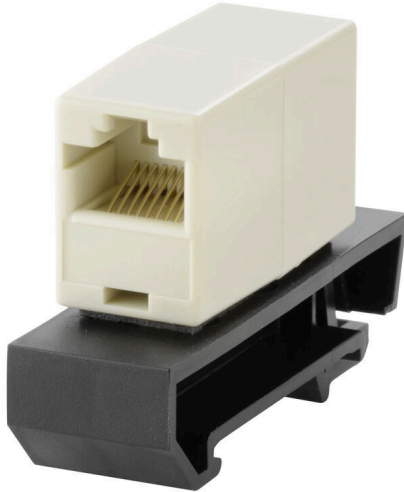

Mounting rail outlet, RJ45 junction design according to IEC 60603-7-51

### General ordering data

Version	Mounting rail outlet, RJ45, IP20, Cat. 5
Order No.	<a href="#">2819260000</a>
Type	IE-TO-RJ45-C-ZP-C5
GTIN (EAN)	4064675330110
Qty.	10 items

## IE-TO-RJ45-C-ZP-C5

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Net weight	13.4 g
------------	--------

## Temperatures

Storage temperature	Operating temperature	-40 °C...80 °C
Installation temperature		

## Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

## General data

Connection 1	RJ45	Connection 2	RJ45
Wiring	Coupling	Colour	beige, black
Housing main material	Plastic, PA 66 UL V0 E63957	Category	Cat. 5
Contact surface	Gold over nickel	Type of mounting	TS 35
Shielding	unshielded	Protection degree	IP20
Plugging cycles	750 (RJ45)		

## Electrical properties

Dielectric strength, contact / shield	≥ 1500 V AC/DC	Dielectric strength, contact / contact	≥ 1000 V AC/DC
Nominal voltage	50 V	Current-carrying capacity at 50 °C	1 A

## General standards

Connector standard	IEC 60603-7-51
--------------------	----------------

## Classifications

ETIM 8.0	EC000313	ETIM 9.0	EC000313
ETIM 10.0	EC000313	ECLASS 14.0	27-44-03-20
ECLASS 15.0	27-44-03-20		

**IE-TO-RJ45-C-ZP-C5**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

